


151082300010

Dimmers

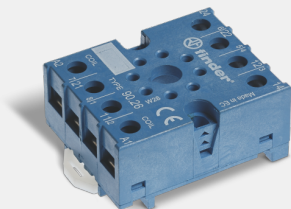

This image is for illustrative purposes only and therefore may not represent the exact product code. Colours may vary.

TECHNICAL DESCRIPTION:

Varialuce (Dimmer) - Master, montaggio su barra 35 mm (EN 60715), larghezza un modulo 17.5 mm, Tipo di alimentazione AC, tensione di alimentazione nominale 230 V, funzionamento da 88 a 253 V, temperatura ambiente da -10 a +50 °C

[BROWSE PRODUCT PAGE](#)

Technical Features:

Commercial Description:

"Master" Dimmer output a 0-10 V/1-10 V master dimming signal to multiple lamp loads that accept this level of input signal. Pushbutton operated, the Type 15.10 can control/drive up to 32 x Type 15.11 slave dimmers or similar devices. By using a number of Type 15.11 slave dimmers on different settings you can control, in unison, multiple lamps of differing technologies via a single 15.10 master dimmer.

Dimensions:

17.5x84x56.5 mm

Manageable with app:

NO

Nominal voltage:

230 V

Supply:

AC supply version

Type of installation:

Master, 35 mm rail (EN 60715) mount, 17.5 mm wide, 0-10 V output

Certifications and quality approvals (according to type):



The information, technical details, data and features contained in this document are subject to change or modification at any time.
It is for information purposes only and does not form the basis of a contract.

Need more information?

[Contact our sales](#) [Find a dealer](#)