


5

4

3

2

1

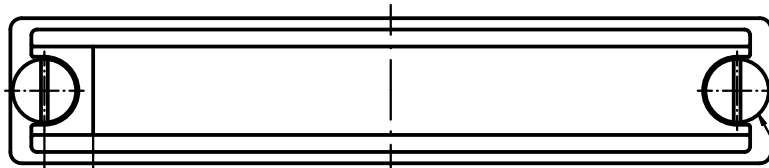


Slotted pan head tapping screws
DIN 7971-ST 2,9x6,5-F
screwing torque=35Ncm +/-5Ncm

4,3

67,1

Slotted pan head tapping screws
DIN 7971-ST 2,2 x 9,5-F
Maximum screwing torque= 0,25 mN


Min. 5,75
Max. 11,6

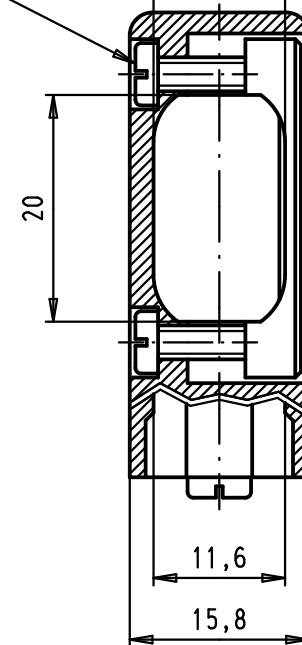

20

11,6

15,8

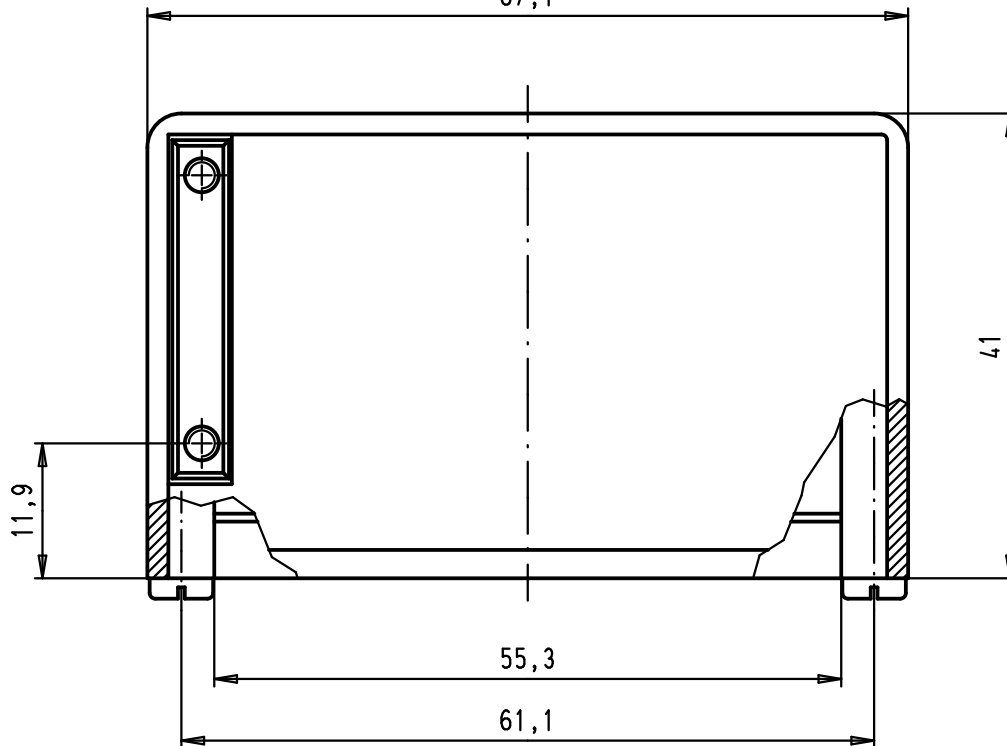


55,3

61,1

11,9

 4,1

				Dat.	Name		D-Sub, hood 50 poles for spring or slide locking, side cable entry	Maßstab/ Scale 1,5:1
			Detail.	28/03/02	CV			
			Insp.	25-MAY-11	JMDV			
			Stand.					
EC03223	25-MAY-11	SD					TB 09 67 050 051X	Blatt/ Page 1 / 1
34886	26/02/08	PK	HARTING EURL F-95972 Paris					
29760	28/03/02	CV						
Mod.	Dat.	Name						
						Sub.		