


push-in sleeve QSH-8-4

Part number: 130625

FESTO

reducing.

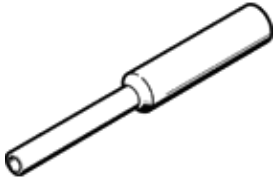

Data sheet

Feature	Value
Size	Standard
Nominal size	2.3 mm
Assembly position	Any
Container size	10
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 6 bar
Temperature dependent operating pressure	-0.95 ... 14 bar
Maritime classification	see certificate
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-] Water as per manufacturer's declaration at www.festo.com
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-10 ... 80 °C
Product weight	0.9 g
Pneumatic connection, port 1	Push-in sleeve QS-8
Pneumatic connection, port 2	Push-in sleeve QS-4
Colour of release ring	blue
Materials note	Conforms to RoHS
Material housing	PBT
Material release ring	POM