



Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JUNE 2023 (235) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Compatible Parts



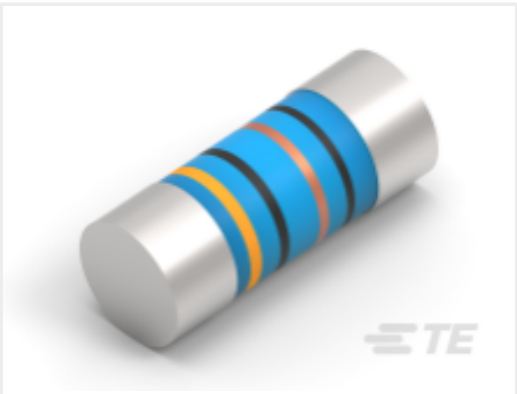


TE Part # 9-2176316-4

MELF SMA-A 330K 1% 50PPM 0207 1W

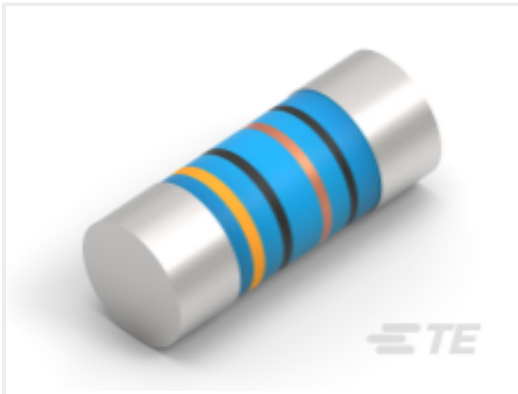


TE Part # 9-2176315-8

MELF SMA-A 1M0 1% 50PPM 0204 0.4 W

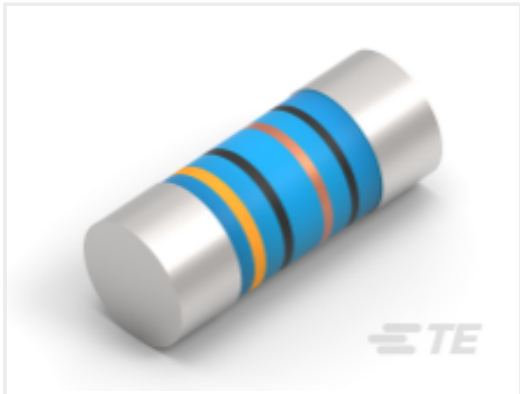


TE Part # 2176316-5

MELF SMA_A 220R 0.1% 15PPM 0207 1W

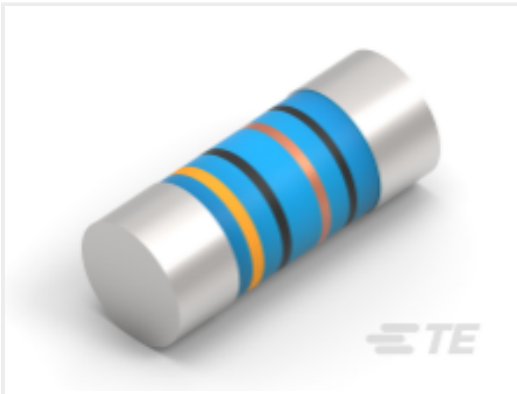

TE Part # 6-2176314-9


MELF SMA-A 10R 1% 50PPM 0102 0.3 W

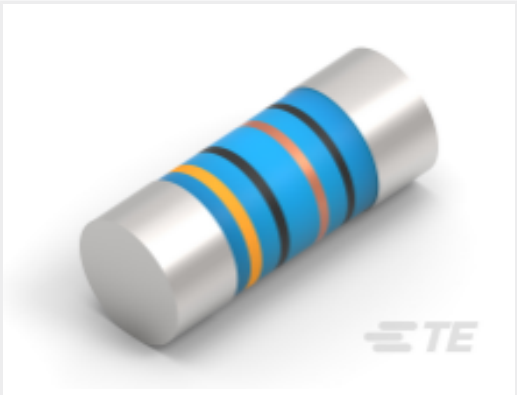

TE Part # 3-2176315-2

MELF SMA_A 39K 0.1% 15PPM 0204 0.4W

Customers Also Bought

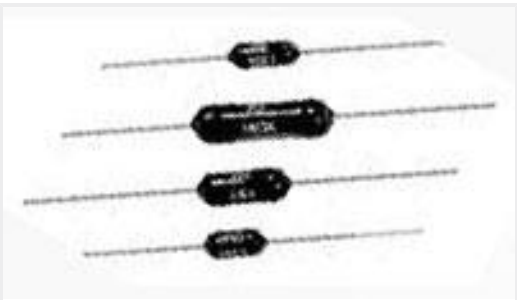

TE Part #5-1879663-8

H8 422R 0.1% 15PPM



TE Part #4-1614894-9

CPF 0805 576K 0.1% 25PPM 1K RL



TE Part #5332225-5

PLUG, TWIN BNC,




TE Part #2-2176345-5

CRGCQ 1210 1K0 1%



TE Part #5332342

TWIN BNC BHD JACK TEF

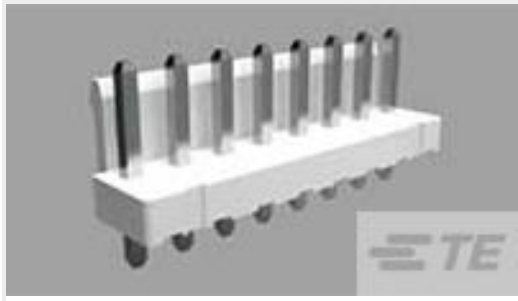


TE Part #1744037-3

03P EC PWR.200 CL HDR ASSY VRT



TE Part #8-1879026-0

YR1 0.1% 442K

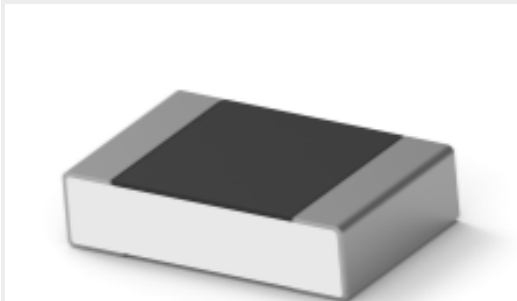


TE Part #8-2176378-2

RQ 0805 69R8 0.1% 10PPM 5K RL



TE Part #3-1676914-6

YR1 0.1% 475K

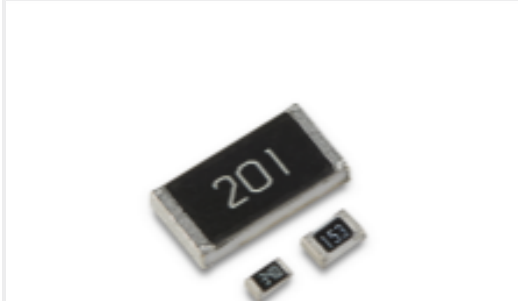

TE Part #2-2176329-1

CRGP 1210 470R 1%

Documents



Product Drawings

MELF SMA_A 47K 0.1% 15PPM 0207 1W

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_3-2176316-3_BA.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_3-2176316-3_BA.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_3-2176316-3_BA.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.