

## DIMMABLE DOWNLIGHT CIO


4126217

9 W - 500lm - 3000K

IP20

50.000 H

 DIMMABLE

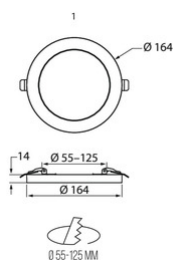

DIMENSIONS	A	B	C
1	14	---	164

GENERAL INFORMATIONS	
Code	4126217
Ean	6435200237569
Family	DIMMABLE DOWNLIGHT CIO
Technology	LED
Operating temperature (° C)	0 - +35

PACKAGING	
Packaging	BOX
Pack	1

LIGHTING DATA	
Kelvin (°)	3000
Lumen	500
Beam (°)	100
Luminous efficacy (lm / W)	55

TECHNICAL FEATURES	
Power (W)	9
Supply voltage (V) / Max (V)	220 / 240
Power frequency (Hz)	50
Hole diameter (mm)	125
Insulation class	2
Dimmer compatibility	SI

## **DIMMABLE DOWNLIGHT CIO**

4126217

9W - 500lm - 3000K

- Panel with side light source and driver incorporated in the frame, total thickness 14mm
- Surface mounted with quick release mounting bracket
- Recessed with adjustable mounting bracket for Ø55-246mm hole (depending on model)
- Dimmable (TRIAC)