



Brand of NTN corporation

## Technical data

### UKFL211H

Bearing units




Grey cast housing, radial insert ball bearing with adapter sleeve, seal with slinger

### KIT CONTENT

UK211G2H, FL211

### VISUAL (S)

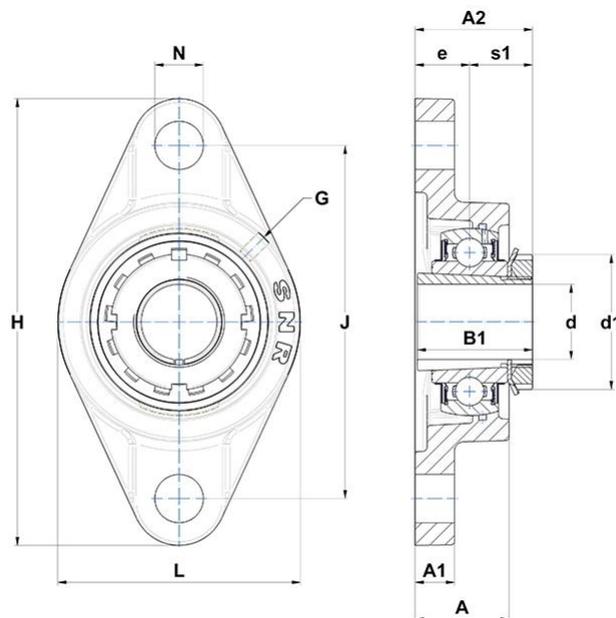

### PRODUCT DEFINITION

<b>Brand</b>	SNR
<b>A - Housing height</b>	43 mm
<b>A1 - Housing foot height / flange height</b>	18 mm
<b>A2 - Total height from mounting surface</b>	54 mm
<b>B - Width of Inner Ring</b>	33 mm
<b>B1 - Overall width Inner Ring</b>	59 mm



**NTN Europe**

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

### PRODUCT DEFINITION

<b>d - Shaft diameter</b>	50 mm
<b>d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve</b>	75 mm
<b>e - Distance mounting surface to bearing center</b>	25 mm
<b>G - Grease fitting</b>	M6x1
<b>H - Housing length, width or diameter</b>	224 mm
<b>J - Mounting holes distance</b>	184 mm
<b>L - Housing width / diameter</b>	130 mm
<b>N - Mounting hole dimension</b>	19 mm
<b>s1 - Distance nut to middle of bearing raceway</b>	29 mm

### PRODUCT PERFORMANCE

<b>C - Dynamic load rating</b>	43550000 mN
<b>C0 - Static load rating</b>	29200000 mN
<b>Operating temperature min.</b>	253,15 °K
<b>Operating temperature max.</b>	373,15 °K

### OTHER FEATURES

<b>Mass</b>	3,06 kg
<b>Adapter sleeve designation</b>	H2311

