

Filler plugs - HC-BS-PG16 - 1674516

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://download.phoenixcontact.com>)


Filler plugs, for Pg screw connections, type Pg16



The illustration shows version HC-BS-PG 21



Key commercial data

Packing unit	10 pc
Minimum order quantity	10 pc
GTIN	 4 017918 135416
Weight per Piece (excluding packing)	18.01 g
Custom tariff number	74153300
Country of origin	Germany

Technical data

Ambient conditions

Degree of protection	IP68
	IP68
Ambient temperature (operation)	-20 °C ... 80 °C

General

Material	Nickel-plated brass
Material, O-ring	NBR
Thread type on connection side	Pg16

Classifications

eCl@ss

eCl@ss 4.0	27140816
eCl@ss 4.1	27140816
eCl@ss 5.0	27143424

Filler plugs - HC-BS-PG16 - 1674516

Classifications

eCl@ss

eCl@ss 5.1	27143424
eCl@ss 6.0	27143424
eCl@ss 7.0	27440209
eCl@ss 8.0	27440209

ETIM

ETIM 2.0	EC000437
ETIM 3.0	EC000437
ETIM 4.0	EC000032
ETIM 5.0	EC000032

UNSPSC

UNSPSC 6.01	30212113
UNSPSC 7.0901	39121712
UNSPSC 11	39121712
UNSPSC 12.01	39121712
UNSPSC 13.2	39121712

Approvals

Approvals

Approvals

GOST

Ex Approvals

Approvals submitted


Approval details

GOST 
--

Drawings

Filler plugs - HC-BS-PG16 - 1674516

Dimensioned drawing

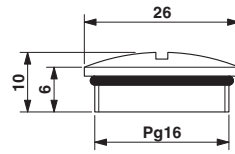

Filler plugs Pg16