



## Double open-ended spanners MOTOR, imperial

### MOTOR 10a



Product no. **40434142**  
GTIN **4018754019847**  
Model **MOTOR 10a 25/32 x 13/16**



#### Label.

Double open-ended spanner Size 25/32 x 13/16 " L.235mm

#### Properties.

- **imperial, differing** end sizes
- straight design, jaws angled 15°
- durable, slim and lightweight design
- high flexural strength due to double-T profile
- STAHLWILLE's rounded finish ensures a non-slip, pleasant feel
- drop-forged, hardened, and cooled in an oil bath
- Chrome Alloy Steel, chrome-plated

## Technologies and features.



#### Double-T profile


Our ring, open-ended and combination spanners have an additional recess in the middle of the tool. Similar to the principle of a double-T beam, this provides a tremendous load capacity and maximum strength whilst reducing weight.



#### Offset Shaft Design

Our spanners are specially designed with additional reinforcement in the load zones where the greatest amount of force is transmitted - namely where the jaw meets the shank - in order to prevent deformation.

Technical drawing.

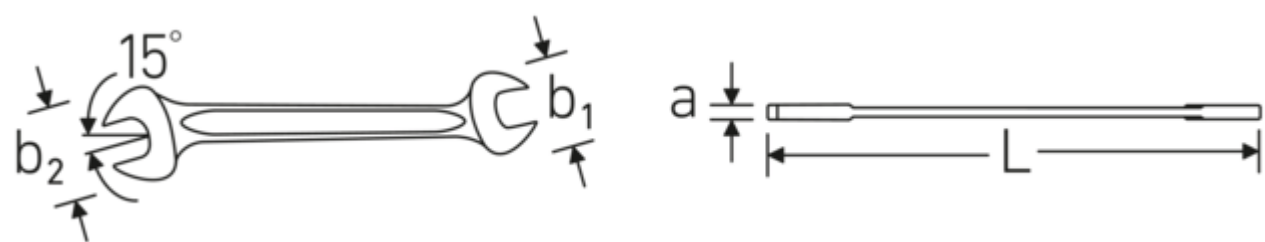

Technical attributes.

|               |                    |
|---------------|--------------------|
| a             | 7,3 mm             |
| b1            | 45 mm              |
| b2            | 47 mm              |
| Length mm (L) | 235 mm             |
| Alloy         | Chrome Alloy Steel |
| Jaws angled   | 15 °               |
| Surface       | chrome-plated      |
| Size 1 [inch] | 25/32 "            |
| Size 2 [inch] | 13/16 "            |

Logistics data.

|                        |                     |
|------------------------|---------------------|
| Depth mm (IFS)         | 232                 |
| Width mm (IFS)         | 48                  |
| Height mm (IFS)        | 7                   |
| WEEE/ElektroG          | nicht ear-pflichtig |
| Length (packaged, mm)  | 245                 |
| Width (packaged, mm)   | 85                  |
| Height (packaging, mm) | 50                  |
| Volume (packaged, dm3) | 1.04125 dm3         |
| Product no.            | 40434142            |
| Weight (gross, kg)     | 1,900               |
| Weight PAP (kg)        | 0,000               |
| Weight PVC (kg)        | 0,012               |
| GTIN                   | 4018754019847       |
| Country of origin AWR  | GERMANY             |
| Region of origin       | Nordrhein-Westfalen |
| Customs tariff no.     | 82041100            |
| Packing standard       | 10                  |
| Weight (g)             | 190 g               |

Variants.

| Product no. | Model No. (ERP)      | Description                                         | GTIN          |
|-------------|----------------------|-----------------------------------------------------|---------------|
| 40431620    | MOTOR 10a 1/4 x 5/16 | Double open-ended spanner Size 1/4 x 5/16 " L.140mm | 4018754019724 |
| 40432024    | MOTOR 10a 5/16 x 3/8 | Double open-ended spanner Size 5/16 x 3/8 L.140mm   | 4018754019731 |
| 40432428    | MOTOR 10a 3/8 x 7/16 | Double open-ended spanner Size 3/8 x 7/16 " L.155mm | 4018754019748 |

|          |                          |                                                         |               |
|----------|--------------------------|---------------------------------------------------------|---------------|
| 40432832 | MOTOR 10a 7/16 x 1/2     | Double open-ended spanner Size 7/16 x 1/2 " L.170mm     | 4018754019755 |
| 40433234 | MOTOR 10a 1/2 x 9/16     | Double open-ended spanner Size 1/2 x 9/16 " L.190mm     | 4018754019762 |
| 40433436 | MOTOR 10a 9/16 x 5/8     | Double open-ended spanner Size 9/16 x 5/8 " L.205mm     | 4018754019779 |
| 40433538 | MOTOR 10a 19/32 x 11/16  | Double open-ended spanner Size 19/32 x 11/16 " L.205mm  | 4018754019786 |
| 40433638 | MOTOR 10a 5/8 x 11/16    | Double open-ended spanner Size 5/8 x 11/16 " L.205mm    | 4018754019793 |
| 40433640 | MOTOR 10a 5/8 x 3/4      | Double open-ended spanner Size 5/8 x 3/4 " L.220mm      | 4018754019809 |
| 40433840 | MOTOR 10a 11/16 x 3/4    | Double open-ended spanner Size 11/16 x 3/4 " L.220mm    | 4018754019816 |
| 40433842 | MOTOR 10a 11/16 x 13/16  | Double open-ended spanner Size 11/16 x 13/16 " L.235mm  | 4018754019823 |
| 40434044 | MOTOR 10a 3/4 x 7/8      | Double open-ended spanner Size 3/4 x 7/8 " L.235mm      | 4018754019830 |
| 40434142 | MOTOR 10a 25/32 x 13/16  | Double open-ended spanner Size 25/32 x 13/16 " L.235mm  | 4018754019847 |
| 40434446 | MOTOR 10a 7/8 x 15/16    | Double open-ended spanner Size 7/8 x 15/16 " L.250mm    | 4018754019861 |
| 40434648 | MOTOR 10a 15/16 x 1      | Double open-ended spanner Size 15/16 x 1 " L.270mm      | 4018754019878 |
| 40435258 | MOTOR 10a 1 1/8 x 1.5/16 | Double open-ended spanner Size 1 1/8 x 1.5/16 " L.300mm | 4018754019908 |

GTIN.

**STAHLWILLE Eduard Wille GmbH**

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal