



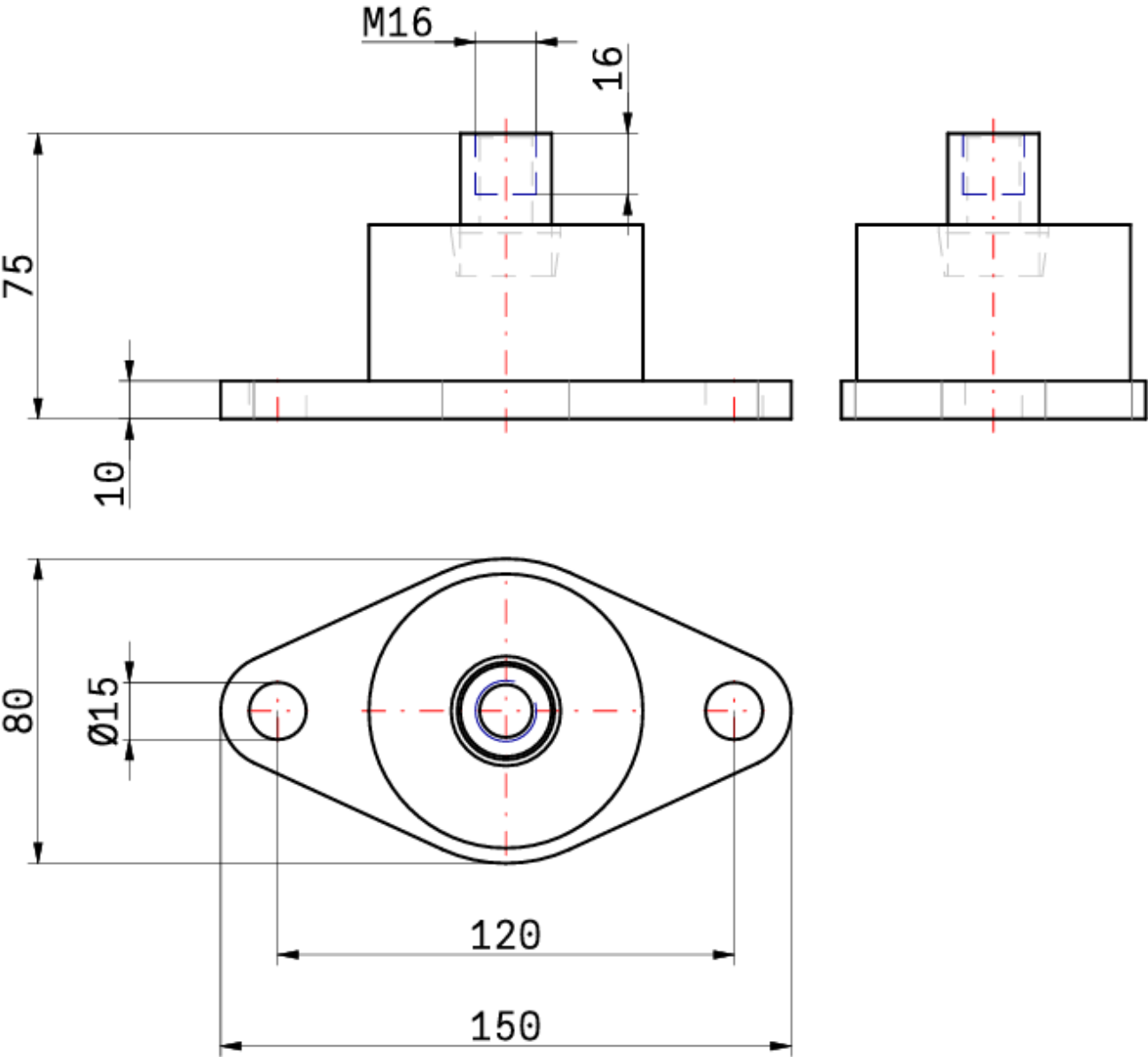

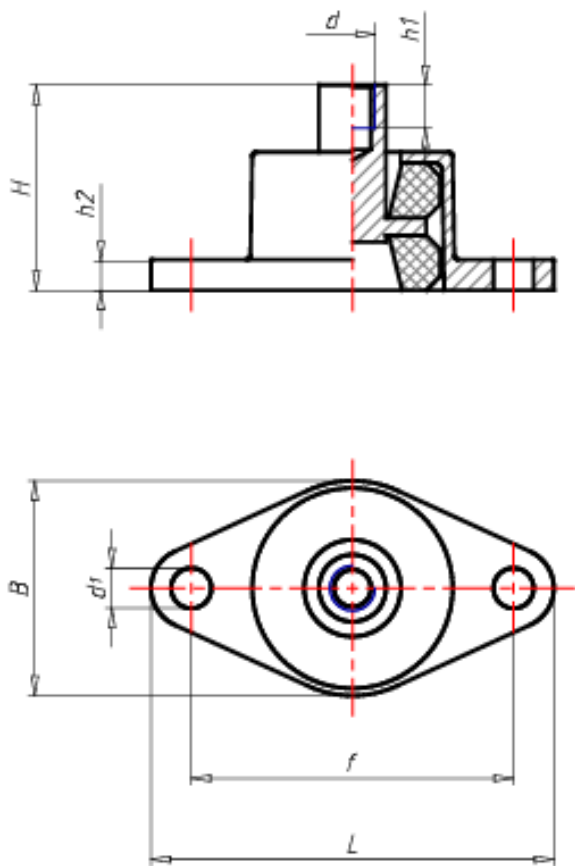

Code	629690
B	80
L	150
H	75
d	M16
d1	15
h1	15
h2	10
f	120
Min load [N]	1400
Max load [N]	6000
Min deflection [mm]	3
Max. deflection [mm]	6.5
Shore A	60
Weight (in g)	60