



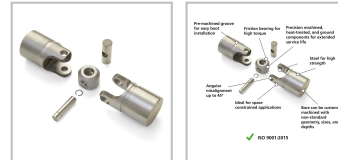

US32-XX-XX-F-KIT

Ruland US32-XX-XX-F-KIT, Machinable Bore Single Universal Joint Kit, Friction Bearing, Steel, 1.995" (50.7mm) OD, 5.500" (139.7mm) Length

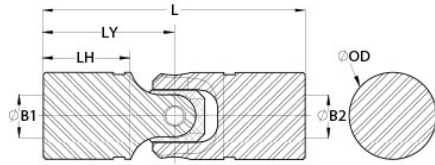

Description

Ruland US32-XX-XX-F-KIT is a single cardan friction bearing universal joint kit that can be machined with a bore size and geometry of the user's choice. It has a 1.995" (50.7mm) OD and 5.500" (139.7mm) length. US32-XX-XX-F-KIT is ideal for applications with space constraints and has higher torque capacity than equivalently sized double universal joints. This plain bearing universal joint is comprised of pins and blocks that are precision machined, selectively heat treated, and ground for high strength, accuracy, and wear resistance. The combination of these components with precision ground and hardened yoke ears allow for a longer lifespan, increased performance in demanding applications, and greater angular misalignment of up to 45° when compared to commodity style single universal joints. US32-XX-XX-F-KIT is made from high grade alloy steel for durability and high strength. It can be combined with boot UBOOT32/51-NI-KIT to protect the joint from unwanted contaminants such as dust or water and self lubricate reducing maintenance time. This single cardan universal joint is manufactured in the USA by Belden Universal for strict control of processes.

Product Specifications

Bore (B1)	No Bore	Small Bore (B2)	No Bore
B1 Max Shaft Penetration	1.700 in (43.2 mm)	B2 Max Shaft Penetration	1.700 in (43.2 mm)
Joint Outer Diameter (OD)	1.995 in (50.7 mm)	Length (L)	5.500 in (139.7 mm)
Yoke Length (LY)	2.750 in (69.9 mm)	Hub Depth (LH)	1.700 in (43.2 mm)
Max Round Bore (Inch)	1.1875 in	Max Round Bore (Metric)	30 mm
Max Hex or Square Bore (Inch)	1.1250 in	Max Hex or Square Bore (Metric)	30 mm
Max Blind Bore (Inch)	1.5000 in	Max Blind Bore (Metric)	38 mm
Max Round Bore w/ Key (Inch)	1-3/16" Bore, 1/4" Keyway	Max Round Bore w/ Key (Metric)	30mm Bore, 8mm Keyway
Peak Torque	21500 in-lb (2429.2 Nm)	Rated Torque	4,300 in-lb (485.8 Nm)
Max Operating Angle	45°	Material Specification	Alloy Steel
Manufacturer	Belden Universal	Country of Origin	USA
Weight (lbs)	4.043000	Recommended Lubricant	LUBRIPLATE No. 1200-2
Matching Boot Cover	UBOOT32/51-NI-KIT	UPC	634529289952
Tariff Code	8483.60.4000	UNSPC	25173810

Note 1 Performance ratings are for guidance only. The user must determine suitability for a particular application.

Prop 65  **WARNING** This product can expose you to the chemical Ethylene Thiourea, known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.