


Kensington H3000 Bluetooth Over-Ear Headset



Kensington's H3000 Bluetooth Headset delivers an immersive and focused experience, the wireless freedom to roam and superior sound technology. Cooling-gel infused memory foam earpads with heat transferring fabric provide all-day comfort, AI-powered environmental noise-cancelling technology suppresses distracting background sounds, LED indicators confirm status and reduce interruptions, music controls with call detection technology simplify transitions and sidetone provides better call engagement. Dynamic 40mm neodymium drivers deliver a superior audio experience for calls and music. The long-life battery with Rapid Charge Technology keeps the headset functioning while it charges. The H3000 is part of Kensington's Professional Video Conferencing ecosystem - providing an integrated experience so you spend more time being productive.

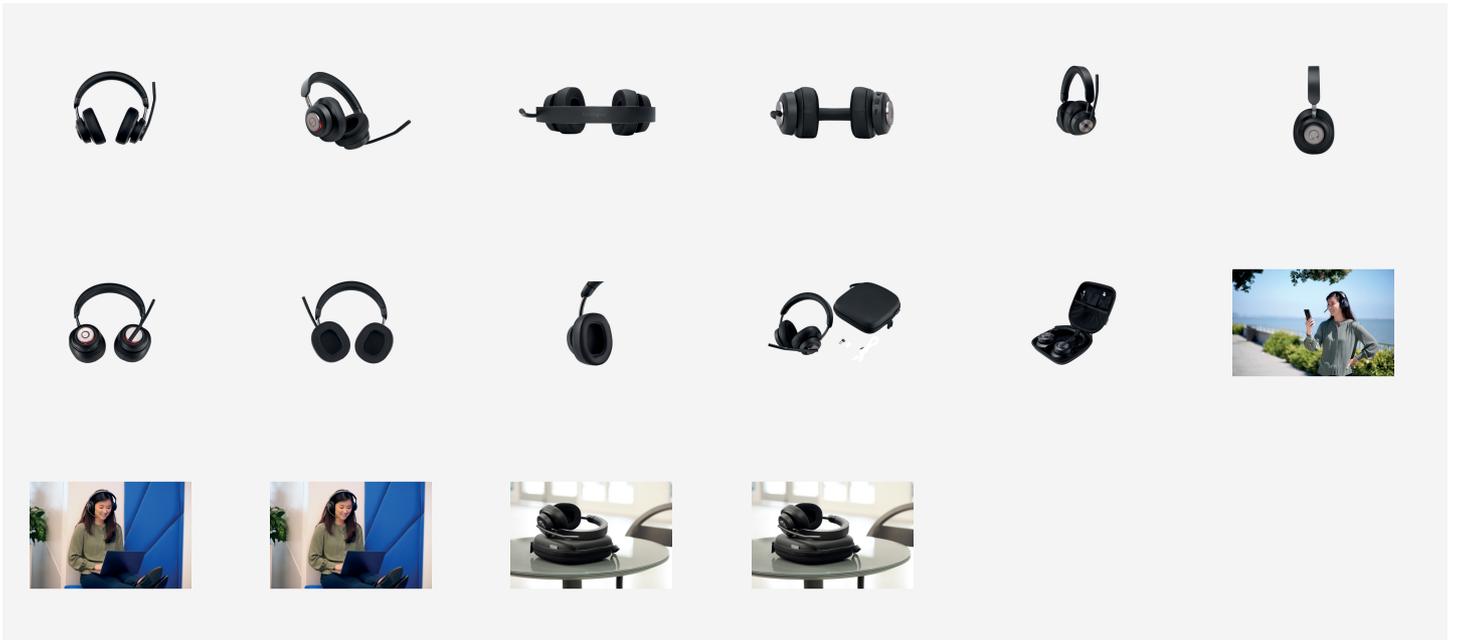

Attributes

Specifications

Number	K83452WW
Colour	black
Dimensions (W x H x D)	210 x 182 x 85 mm
Weight	311 g
Pallet quantity	140
EAN code	85896834526

- Works with popular calling applications (Microsoft Teams, Zoom and more), operating systems (Windows, macOS and Chrome OS), mobile devices (iOS and Android) and voice assistants (Siri and Google Assistant).
- Uses multi-point Bluetooth 5.2 technology to pair with up to 8 devices (with two active at one time).
- Provides 60+ hours for music and 40+ hours for calls.* Rapid Charge Technology provides 8 hours of use after only 15 minutes of charging, allowing you to use your headset while connected to power and provides a full battery after 90 minutes - enabling you to stay productive all day long. * With busy lights off - battery life varies by use.
- Over-ear design with cooling-gel infused memory foam earpads covered in breathable heat transferring fabric, adjustable leatherette headband, a rotating microphone (up to 270°) that can be worn on the right or left side, and rotating joints that allow the earcups to swivel up to 90° for a comfortable, secure fit.
- Passive noise cancellation (PNC) technology allows you to stay focused by blocking out surrounding noise. Convenient flip-to-mute boom microphone supports quick muting needs and built-in hearing protection shields your ears from sounds above 100dBA.
- AI-powered environmental noise-cancelling (ENC) microphone technology suppresses up to 90% of distracting sounds such as keyboard clicks, printers and nearby voices so others can hear your voice clearly. Sidetone confirms you are being heard with voice guidance confirming mute status. Dynamic 40mm neodymium drivers deliver a superior audio experience with HD voice support for calls and music.
- Quick access to volume, play/pause and busy buttons help you maximise productivity. LED lights provide visual confirmation from both earcups of your status so you can stay focused and minimize colleague interruptions.
- Built to accommodate busy professionals, the H3000 allows you to roam up to 30m* from the desk. Includes one USB-C with USB-A adapter, a USB-C charging cable and a premium hard case to protect your headset when travelling.
*Your connected device must be within your line of sight. Wireless range may vary based on users and computing conditions.

- Spend more time collaborating with Kensington's unified video conferencing products and accessories - the most professional and productive way to Communicate like a Pro. 2-year limited warranty included.
-