

nVent CADDY Self-Cutting Cable Tie



The nVent CADDY Self-Cutting Cable Tie is a versatile, tool-free datacom and general bundling solution for large amounts of cable. This simple, yet innovative product features a built-in cutting blade to ensure a secure fastening and a safe, clean tie-off finish. Made from durable 6/6 nylon, the Self-Cutting Cable Tie boasts a robust 22 kg of tensile strength.



FEATURES

- Eliminates sharp edges and protects exposed skin from cuts during installation
- Lock and twist to cut, no cutting tools required
- Different colors including a black UV-protected version to meet specific needs
- RoHS (Restriction of Hazardous Substances Directive) compliant
- Halogen free
- cULus Listed to UL 62275/CSA C22.2 No. 62275, UL Certified to IEC 62275



Part Number	Article Number	Length mm A	Tensile Strength kg	Pack Size pcs	Colour	Min Install Temp	Operating Temperature	Width mm B	Thickness mm	Max Bundle Diameter mm C
CADTIESC8CNAP	601019	200	22	100	Natural	0°C	-20 to 85°C	4,3	1,40	50
CADTIESC8CBAP	601018	200	22	100	UV-Black	0°C	-20 to 85°C	4,3	1,40	50
CADTIESC11CNAP	601001	280	22	100	Natural	0°C	-20 to 85°C	4,3	1,40	76
CADTIESC11CBAP	601000	280	22	100	UV-Black	0°C	-20 to 85°C	4,3	1,40	76
CADTIESC14CNAP	601010	350	22	100	Natural	0°C	-20 to 85°C	4,3	1,40	101
CADTIESC14CBAP	601009	350	22	100	UV-Black	0°C	-20 to 85°C	4,3	1,40	101

Complies with: IEC® 60695-2-11 (Glow Wire Test 960°C)

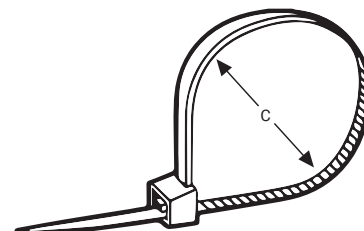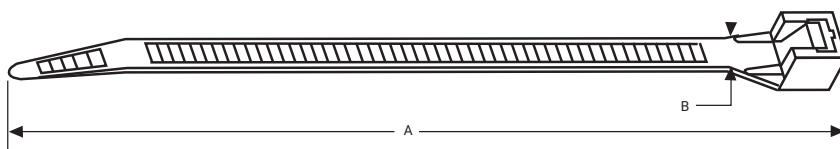

Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO RAYCHEM SCHROFF

