
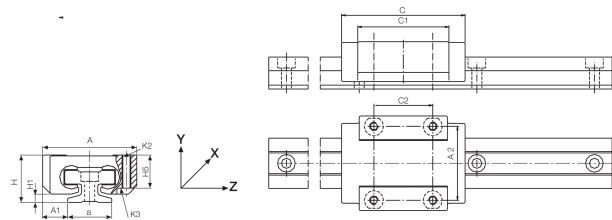


drylin® T miniature guide carriage TW-04

TW-04-12

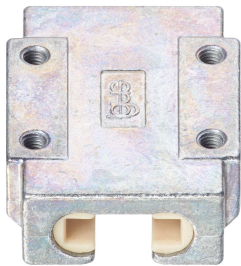

drylin® T miniature guide carriage TW-04

- drylin® T low profile linear carriage of the series 04
- Robust type
- Easy installation
- Captive sliding elements
- Preset bearing clearance
- Optionally configurable as floating bearing version in the y and z direction
- Material: Housing zinc die-casting
- iglidur® J sliding element, mount: TW-04-07, TW-04-07-LLZ: iglidur® J200

Product description

Introducing the drylin® T miniature guide carriage TW-04, a robust solution designed for high load capacity and longevity. Its easy installation allows for quick integration into various applications. Featuring captive sliding elements for safety and preset bearing clearance for smooth movement, this compact carriage excels in tight spaces. Optionally configurable as a floating bearing version, it offers added flexibility in motion. Ideal for reliable and precise guidance, the TW-04 is your go-to choice for demanding environments.

Manufacturing and installation tolerances

H-tolerance	±0,35 mm
-------------	----------

Mechanical properties

Static load capacity Coy	960 N
--------------------------	-------



Dimensions

H	13 mm
A	27 mm
C	34 mm
A1	7.5 mm
A2	20 mm
C1	22 mm
C2	15 mm
H1	2.2 mm
H5	9.5 mm
Thread K2	M3
Thread K3	M2

General properties

Sliding element material	iglidur® J200
size	04-12
Floating bearing	none

Certificates and standards

