



1975Z0

Stay trim and powerful in the danger zone. With ATEX Zone 0 (Category 1) certification, 117 blinding bright lumens, and a true penlight size and shape, the Peli™ 1975Z0 torch is the slimmest and brightest safety approved penlight.

Engineered with an aluminum core and anti-static impact modified PC/PBT, the Peli™ 1975Z0 penlight can survive tough work environments, yet is slim enough to snap into the available helmet mount or hold with your teeth.

The 1975Z0 activates with a click of the tail switch or light pressure for momentary use.

The Peli™ 1975Z0 penlight: Make danger your pen pal.

- 2 AAA Batteries
- Safety Certified ATEX Zone 0 (Category 1)
- Slim and Tough Design
- Full / Momentary Activation Tail Switch
- 117 Lumens
- Helmet Mount (sold separately)



DIMENSIONS

Length 5.75" (14.6 cm)

MATERIALS

Body Anti-static Impact Modified PC/PBT


O-Ring NBR

Lens PC

Shroud Anti-static Impact Modified PC/PBT

Clip Anti-static Impact Modified PC/PBT

COLOURS

 High Visibility Yellow

LIGHT SPECS

Lamp Type LED

POWER

Battery Size AAA

Battery Type Alkaline

Battery Quantity 2

Batteries Included yes

Volts 3.0v

WEIGHT

Weight With Batteries 1.9 oz (54 gr)

Weight Without Batteries 1.0 oz (28 gr)



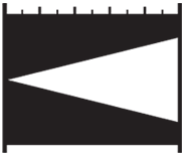


SWITCH

Switch Type Momentary Push Button

Light Modes High

CERTIFICATIONS

ATEX Zone 0

FL1 STANDARD	HIGH
	117 LUMENS
	2h 15mins
	24m
	141cd
	IPX4

Peli

c/ Provença, 388, Planta 7 • Barcelona, Spain 08025 • Phone: +34 934 674 999
info@peli.com • www.peli.com

Document created on 06-27-19