




RS 库存号 517-4443
RS 库存号 517-3276
RS 库存号 517-3333
RS 库存号 517-3298
RS 库存号 517-3355
RS 库存号 517-3412
RS 库存号 517-3260
RS 库存号 517-4437
RS 库存号 517-3305
RS 库存号 517-3361
RS 库存号 517-3383
RS 库存号 517-3327
RS 库存号 517-3311
RS 库存号 517-3377
RS 库存号 517-3399

普通高温箱（无密封、无涂层）

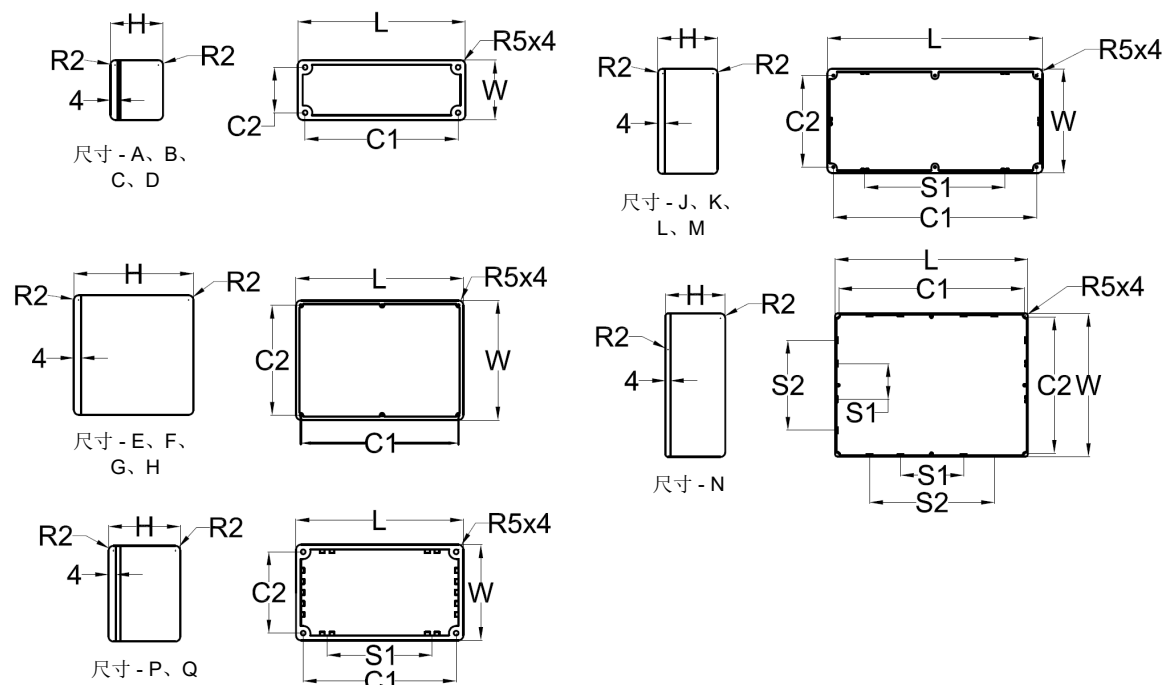

RS 库存号	尺寸号	L	W	H	C1	C2	S1	S2	壁厚
5174443	A	89.1	35.0	30.3	79.3	25.3			1.5mm
5173276	B	114.5	63.6	30.3	104.5	54.2			1.5mm
5173333	C	114.7	89.7	55.1	104.4	79.6			1.5mm
5173298	D	114.4	63.7	55.1	104.6	54.2			1.5mm
5173355	E	171.9	120.9	55.0	160.4	109.3			2mm
5173412	F	171.9	120.9	106.0	160.4	109.3			2mm
5173260	G	222.1	145.9	55.9	211.7	135.4			2mm
5174437	H	222.2	146.0	106.5	211.7	135.4			2mm
5173305	J	275.0	175.0	65.5	264.1	164.0	132.2		2mm
5173361	K	139.1	101.5	76.7	128.7	90.7	64.8		2mm
5173383	L	165.8	127.3	76.3	154.0	116.1	77.1		2mm
5173327	M	119.9	100.0	35.7	108.5	88.4	50.1		2mm
5173311	N	250.2	250.2	100.5	238.0	238.0	79.9	160.0	2.5mm
5173377	P	79.9	54.9	25.5	70.5	45.4	40.0		1.5mm
5173399	Q	60.0	54.9	30.0	50.6	45.4	30.0		1.5mm

1. 基座和盖子材料：铝合金 ADC12
2. 螺钉材料：不锈钢 M3.5x9mm Supadrive 埋头
3. 表面：纯色本色
4. 每侧盖至底座的锥形角为 1.5°