


Mitutoyo

Digital ABS AOS Caliper Constant Measuring Force, 0-180mm

Item number: 573-191-30

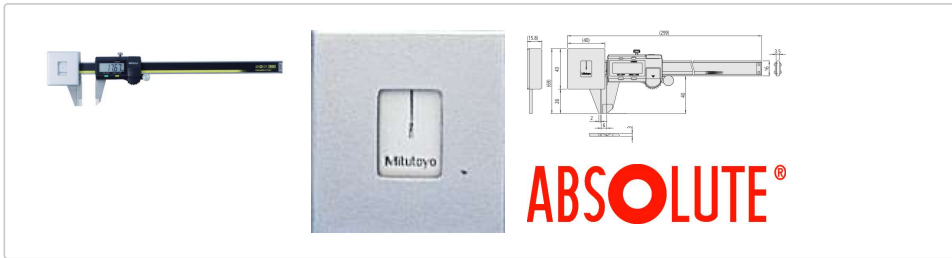

Description

The ABSOLUTE Digimatic calipers have a load cell and help you measure elastic workpieces. They offer you the following benefits:

- Due to their low and constant measuring force these calipers are ideal for measuring elastic workpieces such as plastic and rubber parts that standard calipers cannot measure accurately.
- Large character height (alleviation of fatigue with the high-contrast LCD)
- The ABS (ABSOLUTE) scale requires no origin setting after power-on and also has no limit to response speed.
- Extraordinary battery life

Features

Max. Permissible Error E MPE:	±0,05 mm
Digital step:	0,01 mm
Mass:	253 g
Max. response speed:	Unlimited
Jaw retraction:	0.3 mm
Display:	LCD, character height 9 mm
Delivered:	In a case, including 1 SR-44 battery
Battery life:	Approx. 18000 hours
ORIGIN (ABS-Zero):	Yes
ON/OFF:	Yes
ZERO/ABS:	Yes
Low voltage alarm:	Yes
Data output:	Yes

Accessories

Optional accessories:



Digimatic Cable, Straight, Data Button, 1m

959149

Suggested retail price: **43.00 €***



Digimatic Cable, Straight, Data Button, 2m

959150

Suggested retail price: **50.00 €***







USB Input Tool Direct (Digimatic USB) Digi/Digi2, Straight, with Data Button 06AFM380C


Suggested retail price: **107.00 €***



U-WAVE fit, IP67 Type Wireless Transmitter for Caliper 264-620

	Suggested retail price: 163.00 €*
 U-WAVE fit, Buzzer Type Wireless Transmitter for Caliper 264-621	Suggested retail price: 163.00 €*
 Connection Unit, U-WAVE fit Standard Type 02AZF300	Suggested retail price: 92.00 €*
 Data Hold Unit 959143	Suggested retail price: 30.00 €*

Spare parts

Consumable spares:	
 Battery SR44 1.5V 938882	