





Technical data

51124

One direction thrust ball bearings

VISUAL (S)

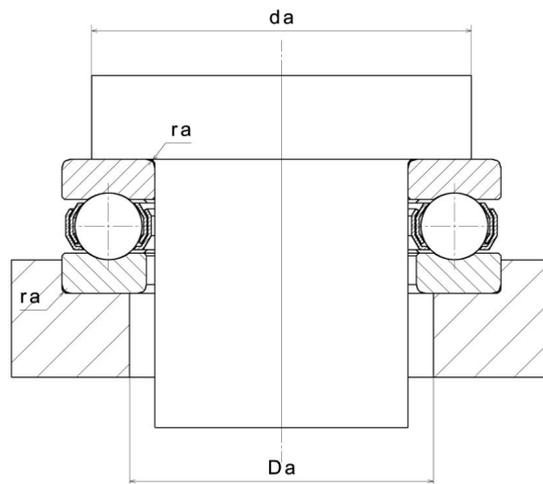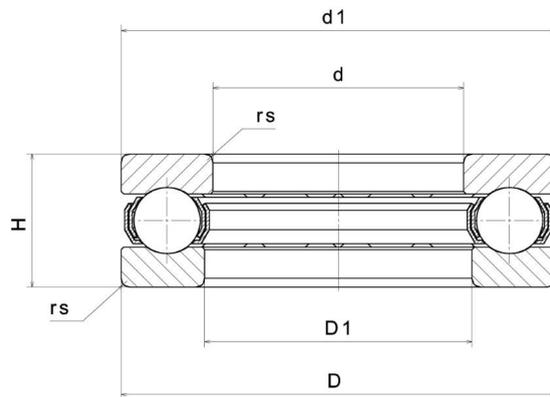

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	120 mm
D - External diameter	155 mm
T - Thrust bearing height	25 mm
rs - Min fillet radius	1 mm
Mass	1,11 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	89000000 mN
C0a - Static axial load rating	310000000 mN
Cua - Limit axial load rating	11800000 mN
N lim - Oil lubrication limit speed	13200 °/s
N lim - Grease lubrication limit speed	9000 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	134 mm
da min - Min shoulder diameter IR	141 mm

