

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Connector set, number of positions: 8, CAT6, material: Die-cast aluminum, salt water resistant, Gender changer

Commercial data

Item number	1249560
Packing unit	1 pc
Minimum order quantity	1 pc
Sales key	*****
Product key	AF7AFX
GTIN	4063151354855
Weight per piece (including packing)	45 g
Weight per piece (excluding packing)	45 g
Customs tariff number	85366990
Country of origin	CN

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Set consists of

HC-STA-D07-BWSCM-EL-AL - Housing

1419250

<https://www.phoenixcontact.com/in/products/1419250>



Panel mounting base D7, with single locking latch, material: Die-cast aluminum, salt water resistant, protective cover material: PA, height: 25.5 mm, cable gland: none, protective cover: yes, Standard, for pin inserts

HC-Q-I-RJ45 GC-F/F - Contact insert

1422590

<https://www.phoenixcontact.com/in/products/1422590>



Contact insert, number of positions: RJ45, size: D7, type : RJ45, Socket, 50 V, 1 A, application: Data, Gender changer

Technical data

Notes

General	Connectors may be operated only when there is no load/voltage.
---------	--

Product properties

Product type	Connector set
Series	HC-D
Application	Data
Type	D7
Sensor type	Ethernet
Number of positions	8
Connection profile	RJ45
Type	RJ45
Protective cover	yes

Insulation characteristics

Overvoltage category	III
Degree of pollution	3

Electrical properties

Rated voltage (III/3)	50 V
Rated surge voltage	0.8 kV
Rated current	1 A
Insulation resistance	100 MΩ
Nominal voltage U_N	50 V
Transmission characteristics (category)	CAT6

Interfaces

Signal type/category	Ethernet CAT6
----------------------	---------------

Material specifications

Material Protective cover	PA
Flammability rating according to UL 94	V0
Seal material	NBR
Housing material	Die-cast aluminum, salt water resistant
Contact material	Copper alloy
Contact surface material	Au
Contact carrier material	PC
Locking latch material	PA

Cable/line

Signal type/category	Ethernet CAT6
----------------------	---------------

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP66
Impact strength	IK06
Ambient temperature (operation)	-40 °C ... 70 °C

Mounting

Mounting type	Panel mounting
---------------	----------------

HC-STA-RJ45GC-BWSC-ELAL - Connector set




1249560

<https://www.phoenixcontact.com/in/products/1249560>

Drawings

Dimensional drawing

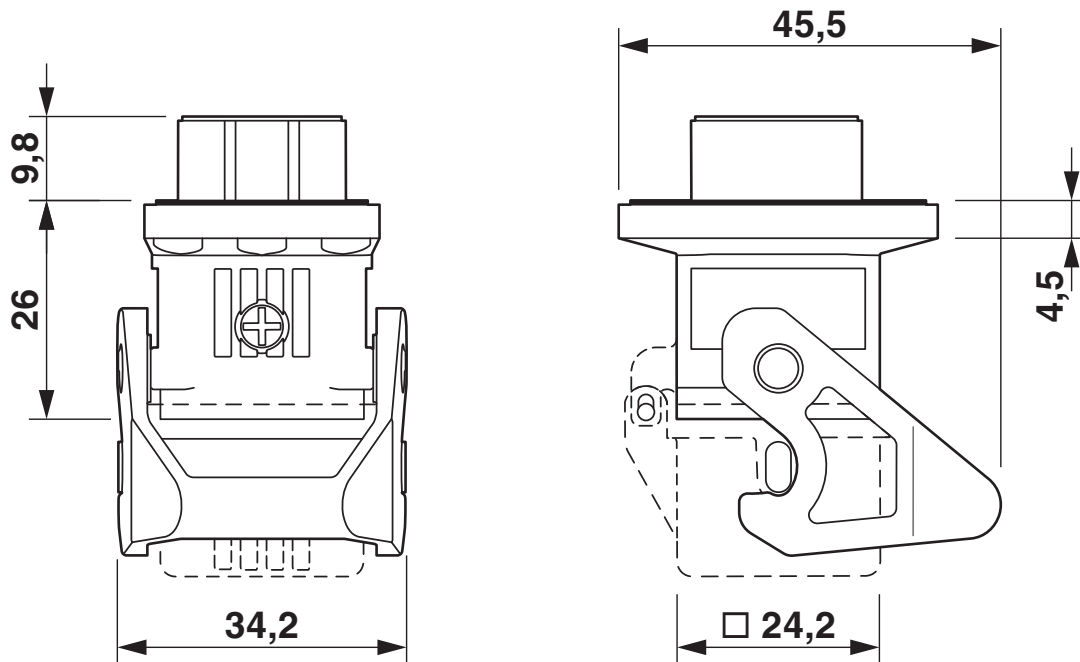

Dimensional drawing

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Classifications

ECLASS

ECLASS-11.0	27440101
ECLASS-12.0	27440113
ECLASS-13.0	27440113

ETIM

ETIM 9.0	EC002636
----------	----------

UNSPSC

UNSPSC 21.0	39121400
-------------	----------

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

HC-STA-RJ45GC-BWSC-ELAL - Connector set



1249560

<https://www.phoenixcontact.com/in/products/1249560>

Accessories

HC-STA-RJ45CT-HT-M20-PLRBK - Connector set

1249554

<https://www.phoenixcontact.com/in/products/1249554>



Connector set, number of positions: 8, CAT6_A, material: PA, connection method: Crimp connection, connection cross section: AWG 24- 27, cable outlet: straight, With RJ45 contact insert, with slotted seal

HC-STA-RJ45I-23-HT-M20-PLRBK - Connector set

1249555

<https://www.phoenixcontact.com/in/products/1249555>



Connector set, number of positions: 8, 1 Gbps, CAT5 (IEC 11801:2002), material: PA, connection method: IDC fast connection, connection cross section: AWG 23- 22, cable outlet: straight, With RJ45 contact insert, with slotted seal

HC-STA-RJ45GC-BWSC-ELAL - Connector set

1249560

<https://www.phoenixcontact.com/in/products/1249560>



HC-STA-RJ45PC-HT-M20-PLRBK - Connector set

1249556

<https://www.phoenixcontact.com/in/products/1249556>



Connector set, material: PA, cable outlet: straight, with slotted seal, with adapter for patch cables

HC-STA-RJ45CT-HS-M20-PLRBK - Connector set

1249557

<https://www.phoenixcontact.com/in/products/1249557>



Connector set, number of positions: 8, CAT6_A, material: PA, connection method: Crimp connection, connection cross section: AWG 24- 27, cable outlet: lateral, With RJ45 contact insert, with slotted seal

HC-STA-RJ45GC-BWSC-ELAL - Connector set

1249560

<https://www.phoenixcontact.com/in/products/1249560>



HC-STA-RJ45PC-HS-M20-PLRBK - Connector set

1249558

<https://www.phoenixcontact.com/in/products/1249558>



Connector set, material: PA, cable outlet: lateral, with slotted seal, with adapter for patch cables

Phoenix Contact 2025 © - all rights reserved

<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.

A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420

info@phoenixcontact.co.in