

Datasheet

ENGLISH


RS PRO, 12 V dc, 223 gcm, Brushed DC Geared Motor, Output Speed 5258 rpm

Stock No: 834-7679



Specifications:

Supply Voltage	4.5 - 15V
Power Rating	12.8 W
Output Speed	5258 rpm
Shaft Diameter	3.175mm
Maximum Output Torque	223 gcm
Length	57.1mm
Dimensions	37 (Dia.) x 57.1mm
Current Rating	1.42 A
Weight	212g

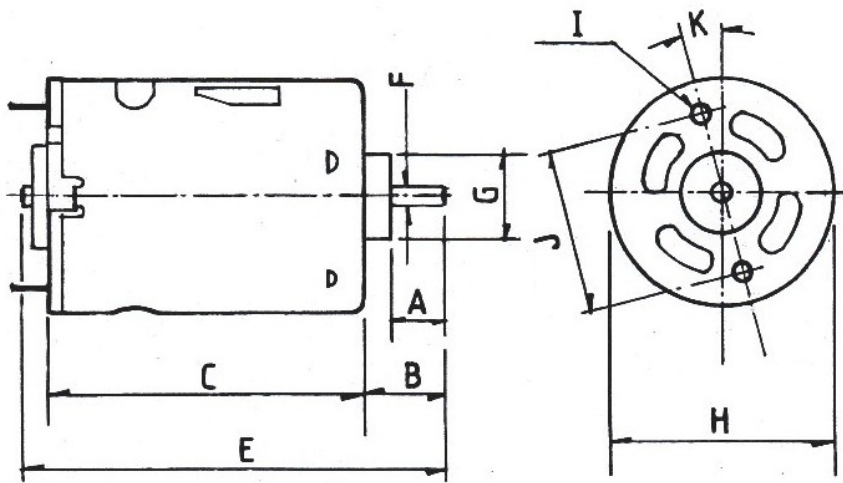

Dimensions	A	B	C	E	F	G	H	I	J
mm	5.5	9.75	57.1	69.2	3.175	14.0	37	M3	25.0

Stall Current RE-540LN at 6v = 10.0A