


PXP6043/A3 Datasheet

 [View Product Page](#)

**Product Name // Plastic Body Front Panel Mount Leaded
USB Connector Sealed 3.0 A Socket Front of Panel To 10
Way Crimp Connector**

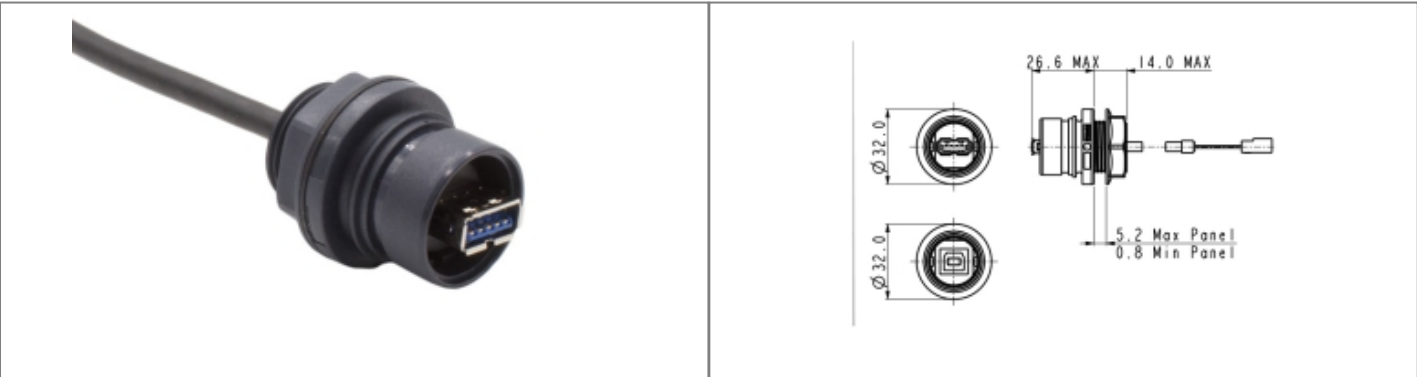

// Product Description:

- Plastic Body Front Panel Mount Leaded Connector
 - Water and dustproof to IP68 & IP69K when mated with compatible connector
 - 30 degree push twist locking, tamperproof lock prevents accidental un-mating
- Sealed Standard USB 3.0 socket to lead cable terminated in 10 way crimp connector
 - PXP6083 Sealing Cap available separately to maintain IP rating of unmated connectors
 - Mate with Plastic Body USB A Cables

// General Information:

Product Display Title:	Plastic Body Front Panel Mount Leaded USB Connector Sealed A Socket Front of Panel To 10 Way Crimp Connector
Product Family:	Circular Data Connectors
Product Series:	6000 Series - USB Buccaneer
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Push-Twist
Current Max:	1A
Data Cable Type:	Sealed A Socket to 10 Way Crimp
Diameter Over Coupling Ring Mm:	32mm
Flamability Rating:	UL94V-0
Function:	Front Panel Mount Connector
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	8 Contacts
Voltage Max:	30V

// Product PDF Links



// Product 3D CAD Model Links



Have a question or project enquiry
you'd like to talk to us about?



[Click Here To Contact Us](#)