


PCB Plugs
1527760000

When good enough just isn't good enough

Weidmüller 

**BLZ 5.08, Screw Clamp: Clamping Yoke, 180°
Orientation, Non-locking**

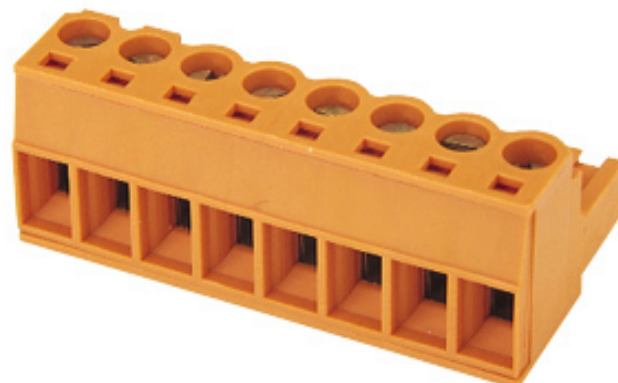

Representative Photo

Technical Information

Connector Options	Socket Block
Pitch	5.08 mm
Poles	15
Connection Method	Screw Clamp: Clamping Yoke
Orientation	180°
Locking	No
Color	Orange
Wire Size	#22...12 AWG
Rated Voltage UL	300 V
Rated Current UL	15 A
Configuration	Single row

Technical Data

	UL	CSA	VDE
Rated Voltage	300 V		
Rated Current	15 A		

Additional Data

Suggested Accessories

Product Liability The above information describes our products. It does not constitute guaranteed properties and is not intended to affirm the suitability of a product for a particular application. Regrettably, omissions and exceptions cannot be completely ruled out. Technical data are always specified by their average values. Exact data and the tolerances which apply to our processes can be requested from:

Weidmüller - North America
United States 001 (800) 849-9343
Canada 001 (800) 268-4080

or

Weidmüller - Germany
Telephone operator 0049 (-5252) 960-0