

## RJ Industrial Cable Assembly,0.6m

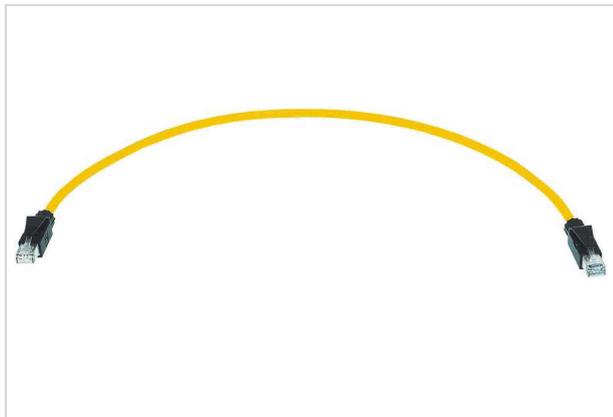


Image is for illustration purposes only. Please refer to product description.

Part number	09 45 751 1554
Specification	RJ Industrial Cable Assembly,0.6m
HARTING eCatalogue	<a href="https://harting.com/09457511554">https://harting.com/09457511554</a>

### Identification

Category	System cabling
Series	RJ45
Element	Cable assemblies
Specification	Pre-assembled on both sides
Connector 1	HARTING RJ Industrial®
Connector 2	HARTING RJ Industrial®
Type of cable	Copper cable (round)

### Version

Cable length	0.6 m
Number of cores	8
Core structure	4x 2x AWG 26/7

### Technical characteristics

Transmission characteristics	Cat. 6 <sub>A</sub> Class E <sub>A</sub> up to 500 MHz
Data rate	10 Mbit/s
	100 Mbit/s
	1 Gbit/s
	2.5 Gbit/s
	5 Gbit/s
	10 Gbit/s

### Material properties

Material (cable)	PVC
------------------	-----



**Pushing Performance**  
Since 1945

## Material properties

Colour (cable)	Yellow
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Commercial data

Packaging size	1
Net weight	67.5 g
Country of origin	Romania
European customs tariff number	85444290
GTIN	5713140063815
eCl@ss	27060308 Patch cord copper (data cable)
UNSPSC 24.0	26121609