

# Diffused On Board Tape



### Key Features:

- Available in four different colour temperatures
- CRI ≥80
- Supplied with 5M reels; cuttable every 45.45mm
- Continuous diffused LED, no spotting
- Fitted with 3M adhesive tape
- High lumen output
- 3 years warranty

### DIFFUSED ON BOARD TAPE SPECIFICATION


Part Code	B5-DOB-24-528-F8	C0-DOB-24-528-F8	D0-DOB-24-528-F8	E0-DOB-24-528-F8	F0-DOB-24-528-F8
Voltage	24VDC	24VDC	24VDC	24VDC	24VDC
Power Consumption	10W/M	10W/M	10W/M	10W/M	10W/M
LED Qty	528	528	528	528	528
LED Pitch	1.9mm	1.9mm	1.9mm	1.9mm	1.9mm
Lumen Output	970lm/M	970lm/M	1050lm/M	1050lm/M	1050lm/M
CRI	80Ra	80Ra	80Ra	80Ra	80Ra
Cut Points	45.45mm	45.45mm	45.45mm	45.45mm	45.45mm
CCT	2500K	3000K	4000K	5000K	6000K
IP Rating	IP20/65	IP20/65	IP20/65	IP20/65	IP20
Back Adhesive	3M	3M	3M	3M	3M
Working temperature	-20°C ~ +40°C	-20°C ~ +40°C	-20°C ~ +40°C	-20°C ~ +40°C	-20°C ~ +40°C
Width Dimensions	8/12mm	8/12mm	8/12mm	8/12mm	8/12mm

LED Flexi Strip width & IP rating part codes  
 8mm width ~ IP20 = 20    12mm Width ~ IP65 = 65    ie: B5-DOB-24-528-F8-20




### Mechanical

#### IP20 Diagram

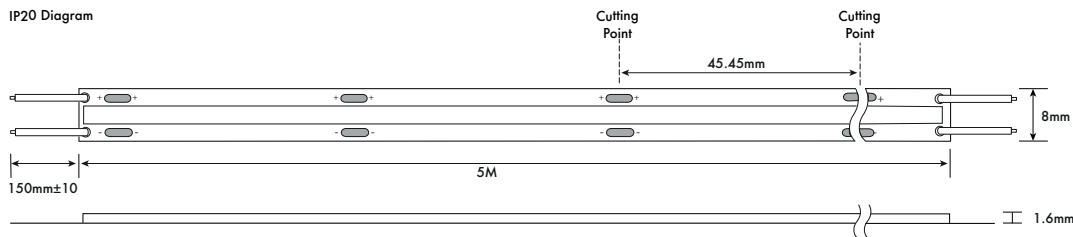

#### IP65 Diagram

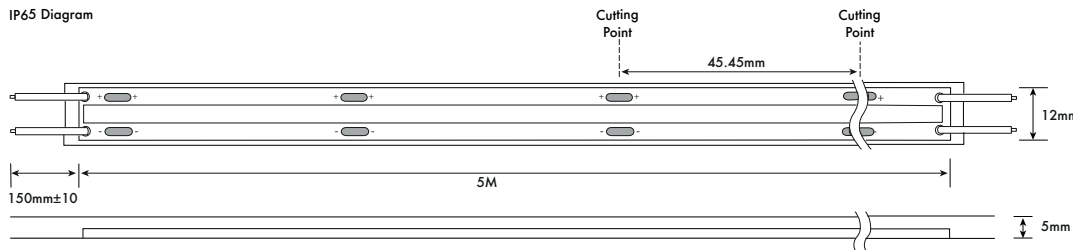

PowerLed  
 Orion House  
 Calleva Park  
 Aldermaston  
 Berkshire  
 RG7 8SN

Contact:  
 Tel: 0118 9703856  
 enquiries@powerled.uk.com  
 www.powerled.uk.com

