


Datasheet

RS 6 Core Unscreened Industrial Cable, PVC Sheath, 4.8mm OD, 0.22 mm² CSA 1 A, 440 V, 25m

Stock Number - 660-4049

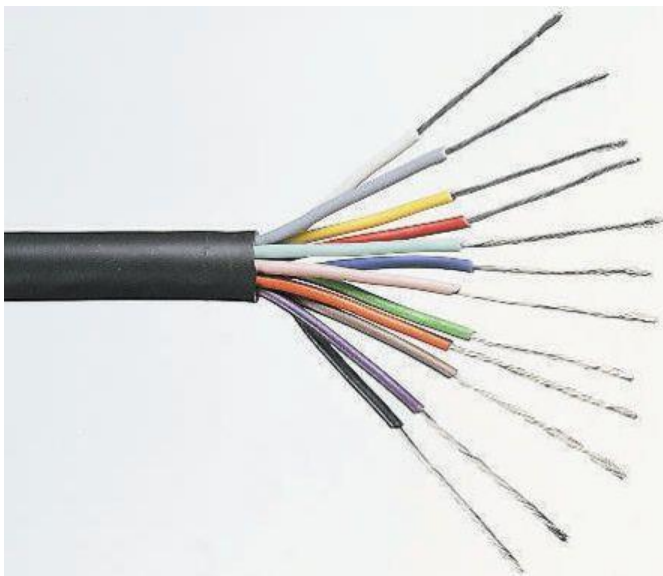

Description:

Rated Temperature (oC): -20 ~ 80

Rated Voltage (V):440

Flammability Test: IEC60332-1



ENGLISH

Conductor: Tinned Copper
Conductor Dia. (mm): $0.20 \pm 0.008 \times 7$
Insulation: PVC
Insulation Dia. (mm): $1.2 \pm 0.05 \times 6C$
Fiiler: 1.2 PVC Strip
Tape: Mylar Spiral
Coverage: $\geq 115\%$
ID Thread : Green, White/Green
A rip cord : 210 D
Jacket: FR-PVC
Outer Dia. (mm): 4.6 ± 0.1

Colour:
The colour of the insulation: Red , Blue , Green ,
Yellow ,
White , Black
The jacket colour: Black
Marking(3times/m):
RS 6604049 7 - 2 - 6A

Electrical Characteristics:**Max.Conductor DC Resistance at 20°C (Ω /Km) :**

<92

Min.Insulation DC Resistance at 20°C ($M\Omega$ *KM) :

>200

Current Rating : 1 A