

## Universal socket strip 3-fold (type E)

Item-no.: 0200x02032301 (1,5 m cord) | 0200x02032303 (3 m cord) | 0200x02032305 (5 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m or 5 m power cord)


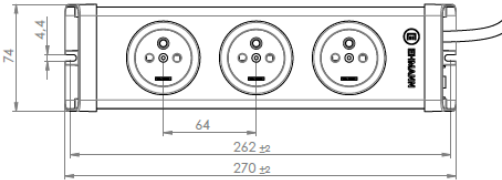
Expanded contact protection by using a shutter

End caps with mounting possibility



## Universal socket strip 3-fold (type E)

### Technical Data

<p><b>3.600 W</b> <b>Power</b></p>	<p><b>230 V ~ (+/- 10%) / 50 Hz</b> <b>Rated voltage</b></p>	<p><b>16 A</b> <b>Rated current</b></p>									
<p>Power cord: H05VV-F 3G 1,5 mm<sup>2</sup>          Plug: CEE 7/7 plug type EF, angled          Sockets: earthing contact type E (French standard)          Safety class: IP20</p>											
<div style="text-align: center;">  <p>(similar illustration)</p> </div>											
<table border="0"> <tr> <td>Item-no. 0200x02032301 (1,5 m cord)</td> <td>EAN 4012096013235</td> <td>PU 10</td> </tr> <tr> <td>Item-no. 0200x02032303 (3 m cord)</td> <td>EAN 4012096007814</td> <td>PU 10</td> </tr> <tr> <td>Item-no. 0200x02032305 (5 m cord)</td> <td>EAN 4012096013372</td> <td>PU 10</td> </tr> </table>		Item-no. 0200x02032301 (1,5 m cord)	EAN 4012096013235	PU 10	Item-no. 0200x02032303 (3 m cord)	EAN 4012096007814	PU 10	Item-no. 0200x02032305 (5 m cord)	EAN 4012096013372	PU 10	<p>270 x 74 x 47 mm          Dimensions (L x W x H)          262 mm          Fixing dimension (X)</p>
Item-no. 0200x02032301 (1,5 m cord)	EAN 4012096013235	PU 10									
Item-no. 0200x02032303 (3 m cord)	EAN 4012096007814	PU 10									
Item-no. 0200x02032305 (5 m cord)	EAN 4012096013372	PU 10									