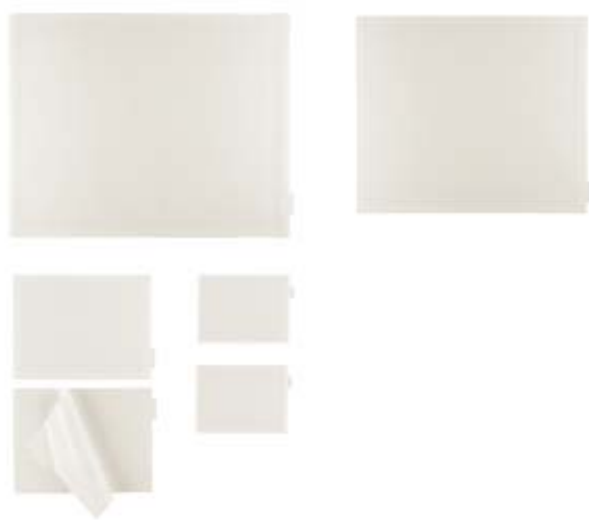


# SIEMENS

## Product data sheet

**6AV6671-3DC00-0AX0**


PROTECTIVE MEMBRANE 10" 292MM X 248MM,  
FOR THIN CLIENT 10" AND MP 277 10" TOUCH TO  
ES14,  
W:292.0 H:248.0 D:0.125,  
10 PIECES PER PACKAGING UNIT

| Installation type/mounting            |        |
|---------------------------------------|--------|
| Mounting in portrait format possible  | Yes    |
| Mounting in landscape format possible | Yes    |
| Standards, approvals, certificates    |        |
| CE                                    | Yes    |
| Ambient conditions                    |        |
| Operating temperature                 |        |
| Operating temperature range, max.     | 50 °C  |
| Operating temperature range, min.     | 0 °C   |
| Storage/transport temperature         |        |
| Min.                                  | -20 °C |
| max.                                  | 60 °C  |
| Relative humidity                     |        |
| max. relative humidity                | 90 %   |
| Films                                 |        |

|                              |                     |
|------------------------------|---------------------|
| printable with laser printer | Yes                 |
| Mechanics/material           |                     |
| Plastic                      | Yes ; Nonreflecting |
| Dimensions                   |                     |
| Width                        | 292 mm              |
| Height                       | 248 mm              |
| Thickness                    | 0.125 mm            |
| Scope of supply              |                     |
| Delivery unit in items       | 10                  |
| Status                       | May 3, 2012         |