


2537450 DSBG-200-50-P-N3 standards-based cylinder - Series: All

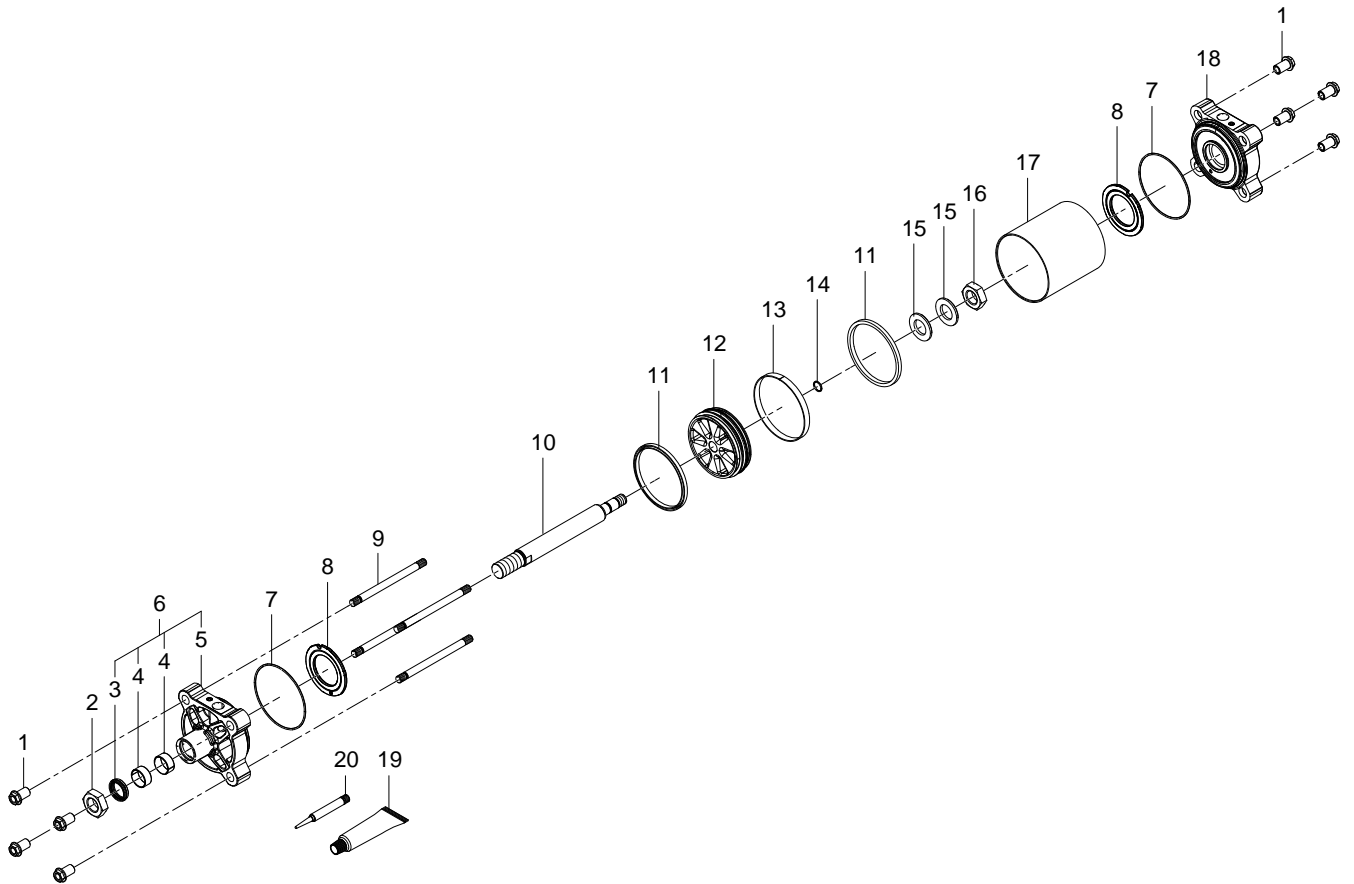

## 2537450 DSBG-200-50-P-N3 standards-based cylinder - Series: All

Pos.	Part no.	Type	Note	Qty.	Unit
A	8025175	DSBG-200- - Set of wearing parts	Spare parts: 3, 7, 8, 11, 13, 14, 19, 20	1	PC
1	1721255	DSBG-160/200 Collar nut	Tightening torque 100 Nm / 73.8 lbf ft Use locking compound. See position 20	8	PC
2	214862	DIN 439-B-M36X2-04 Hex nut		1	PC
3	224143	WIFC6-40X50X11,5-NBR Wiper seal	Grease using during assembly. See position 19	1	PC
4		40X44X20-4020-DP4 Bearing bushing	Not available separately, see position 6	2	PC
5		DSBG-200-P Bearing cap	Not available separately, see position 6	1	PC
6	2307513	DSBG-200-P Bearing cap module		1	PC
7		B-192X4-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 19	2	PC
8		DSBG-160/200-NBR80 Cushioning	Not available separately, see position A	2	PC
9	8025390	DSBG-YZ-200- - Tie rod	When ordering please specify the stroke (see type plate)	4	PC
10	8025353	DSBG-YP-200- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
11		200X180X14 PERBUNAN Lip ring	Not available separately, see position A Grease using during assembly. See position 19	2	PC
12		DSBG-200 Piston	Not available	1	PC
13		DN -200 Guiding band	Not available separately, see position A	1	PC
14		B-20X2-N-NBR70 O-ring ISO3601	Not available separately, see position A Grease using during assembly. See position 19	1	PC
15	200413	DIN 125-B-25 Disc		2	PC
16	200401	DIN 439-B-M24-04 Hex nut	Tightening torque 330 Nm / 243.4 lbf ft Use locking compound. See position 20	1	PC
17		DSBG-200-... Cylinder barrel	Not available Grease using during assembly. See position 19	1	PC
18	2310768	DSBG-200-P End cap module		1	PC
19	684474	LUB-KC1 SILIKONFREI 20ML Lubricating grease		2	PC
20	8181257	CYBERBOND TM44 TB3ML Adhesive bonding agent		1	PC