



# Halogen Classic Candle B35

Halogen Classic 28W B22 240V B35 1CT

Philips Halogen Classic Candle light bulbs offer the classical shape you are used to. This new 'classic' gives high-quality light, is dimmable and starts immediately.

## Product data

### • General Characteristics

Cap-Base	BC [BC]
Bulb	B35 [B 35mm]
Bulb Finish	Clear
Burning Position	any [Any/Universal]
Nominal Lifetime	2000 hr
Rated Lifetime	2000 hr
Rated Lifetime (years)	2 an

### • Light Technical Characteristics

Colour Rendering Index	100 Ra8
Colour Temperature	2800 K
Colour Temperature Technical	2800 K
Lamp Luminous Flux	370 Lm
Rated Luminous Flux	370 Lm
Lamp Luminous Efficacy	12.4 Lm/W
LLMF - end nominal lifetime	80 (min) %

### • Electrical Characteristics

Rated Wattage	28.0 W
Lamp Wattage	28 W
Technical Lamp Power	28 W
Power Factor	1 -
Voltage	240 V
Lamp Current	0.12 A
Dimmable	yes
Wattage Equivalent	35 W
Starting Time	0.0 s

Warm-up Time to 60% Light Outp	instant full light
--------------------------------	--------------------

### • Environmental Characteristics

Energy Efficiency Label (EEL)	D
Energy consumption kWh/1000h	28 kWh

### • Measuring Conditions

Switching cycle	8000X
-----------------	-------

### • Luminaire Design Requirements

Cap-Base Temperature	130 (max) C
----------------------	-------------

### • Product Dimensions

Overall Length C	94.5 (max) mm
Diameter D	36 (max) mm

### • Product Data

Order code	252736 02
Full product code	872790025273602
Full product name	Halogen Classic 28W B22 240V B35 1CT
Order product name	Halogen Classic 28W B22 240V B35 1CT/15
Pieces per pack	1
Packing configuration	15
Packs per outerbox	15
Bar code on pack - EAN1	8727900252736


**PHILIPS**

# Halogen Classic Candle B35

Bar code on  
outerbox - EAN3 8718696462416  
Logistic code(s) -  
12NC 925639845508


Net weight per piece 24.500 gr

## Dimensional drawing

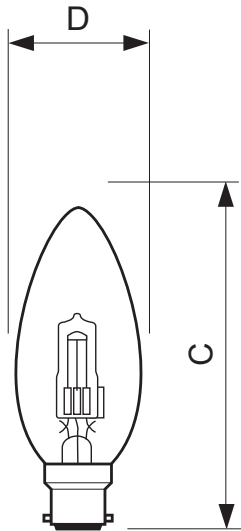

## Halogen Classic 28W B22 240V B35 1CT

 Product	C (Max)	D (Max)
HalClass 28W B22 240V B35 CL	94.5	36



B22



© 2015 Koninklijke Philips N.V. (Royal Philips)  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2015, September 24  
data subject to change