


# Coloured Neodymium Shallow Pots with Countersunk Hole

## Typical Applications

- Available in a variety of colours to suit any environment
- With countersunk hole for screw fixing

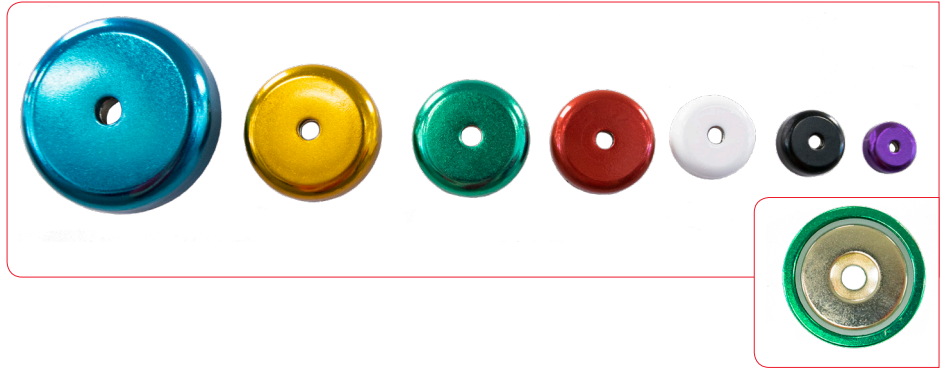

Product Number Black	Product Number White	Product Number Red	Product Number Gold	Product Number Blue	Product Number Green	Product Number Purple	Diameter mm	Thickness mm	Hole Size mm	Screw Head mm	Weight g	Pull Force kg	Unit/ Pack
E1100/NEO/BLK/RS	E1100/NEO/W/RS	E1100/NEO/R/RS	E1100/NEO/GO/RS	E1100/NEO/B/RS	E1100/NEO/G/RS	E1100/NEO/P/RS	16	5	3.5	M3	7	6	10
E1101/NEO/BLK/RS	E1101/NEO/W/RS	E1101/NEO/R/RS	E1101/NEO/GO/RS	E1101/NEO/B/RS	E1101/NEO/G/RS	E1101/NEO/P/RS	20	7	4.5	M4	15	9	10
E1102/NEO/BLK/RS	E1102/NEO/W/RS	E1102/NEO/R/RS	E1102/NEO/GO/RS	E1102/NEO/B/RS	E1102/NEO/G/RS	E1102/NEO/P/RS	25	8	5.5	M5	24	19	10
E1103/NEO/BLK/RS	E1103/NEO/W/RS	E1103/NEO/R/RS	E1103/NEO/GO/RS	E1103/NEO/B/RS	E1103/NEO/G/RS	E1103/NEO/P/RS	32	8	5.5	M5	39	32	10
E1104/NEO/BLK/RS	E1104/NEO/W/RS	E1104/NEO/R/RS	E1104/NEO/GO/RS	E1104/NEO/B/RS	E1104/NEO/G/RS	E1104/NEO/P/RS	40	8	6.5	M6	69	52	5
E1105/NEO/BLK/RS	E1105/NEO/W/RS	E1105/NEO/R/RS	E1105/NEO/GO/RS	E1105/NEO/B/RS	E1105/NEO/G/RS	E1105/NEO/P/RS	48	11	8.5	M8	120	75	1
E1106/NEO/BLK/RS	E1106/NEO/W/RS	E1106/NEO/R/RS	E1106/NEO/GO/RS	E1106/NEO/B/RS	E1106/NEO/G/RS	E1106/NEO/P/RS	60	15	8.5	M8	243	135	1