



Scheda tecnica prodotto

LUHR 25-2LS



Gruppo di guida assiale con 2 tenute

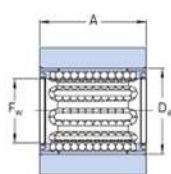

LUHR
With double lip seal

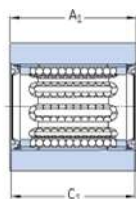

LUHR
With shaft seals

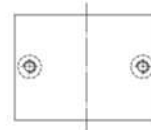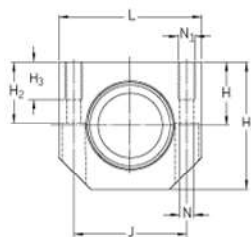

A [mm]:	40
D = Da [mm]:	35
Fw [mm]:	25
H [mm]:	27
H1 [mm]:	54
H2 [mm]:	26
H3 [mm]:	18
J [mm]:	48
L [mm]:	62
N [mm]:	6.6
N1:	M8
Ranghi sfere [#]:	7
Cdyn [N]:	2120

Data: 21/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Scheda tecnica prodotto

LUHR 25-2LS

Gruppo di guida assiale con 2 tenute

C0 [N]:	1560
Massa [kg]:	0.25
A1[mm]:	49
C1[mm]:	48

Data: 21/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.