
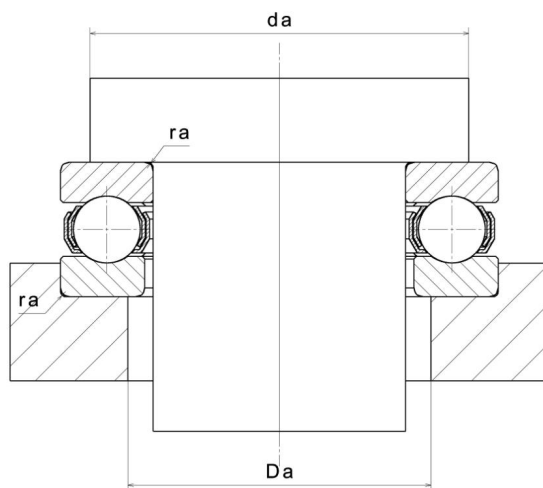


Technical data

51113

One direction thrust ball bearings

VISUAL (S)

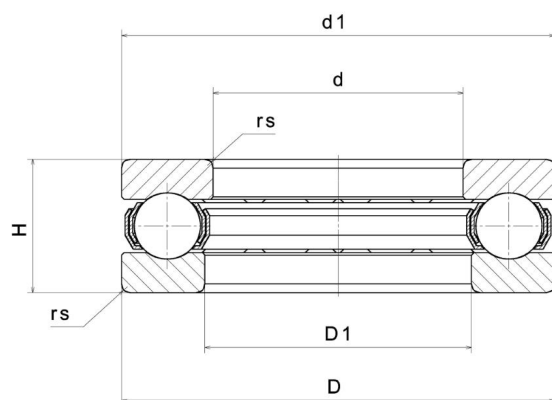

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	65 mm
D - External diameter	90 mm
T - Thrust bearing height	18 mm
rs - Min fillet radius	1 mm
Mass	0,338 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	41500000 mN
C0a - Static axial load rating	117000000 mN
Cua - Limit axial load rating	5300000 mN
N lim - Oil lubrication limit speed	21000 °/s
N lim - Grease lubrication limit speed	14400 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	75 mm
da min - Min shoulder diameter IR	80 mm

