


FEATURES

- **Flexible Design:** Easily adapts to different shapes and surfaces, allowing for versatile installation.
- **IP54 Rating:** Provides protection against dust and splashing water, suitable for indoor and semi-outdoor use.
- **Blue LED Colour:** Enhances visual appeal with a striking blue light, ideal for decorative purposes.
- **16.6 mm LED Pitch:** Ensures uniform light distribution across the strip.
- **60 LEDs per Metre:** Offers bright and consistent illumination.
- **4.8 W/m Power Consumption:** Energy-efficient, reducing operational costs.
- **70 lm/m Luminous Flux:** Delivers adequate brightness for ambient lighting.
- **24 V DC Voltage:** Compatible with standard low-voltage power supplies.

RS PRO Flexible LED Strip Light, Blue, 5m

RS Stock No: 558-402

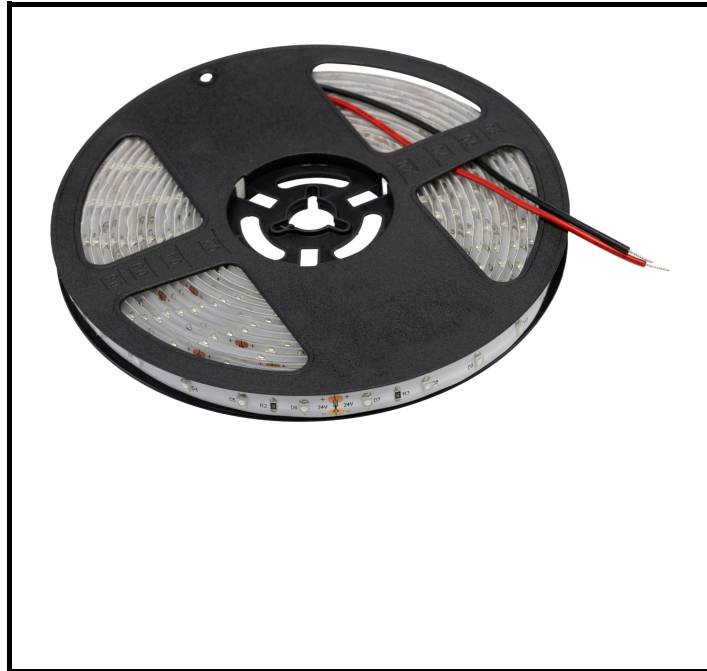

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO flexible LED strip light offers a versatile lighting solution ideal for various applications. With a vibrant blue hue, it is perfect for creating ambient lighting effects. The strip is designed to be energy-efficient, consuming only 4.8 W per metre, making it a cost-effective choice for continuous use.

General Specifications

Flexible/Rigid	Flexible
LED Colour	Blue
LED Pitch	16.6 mm
Number of LEDs Per Metre	60
Product Type	LED Strip Light
Typical Luminous Flux (lm/m)	70 lm/m

Protection Category

IP Rating	IP54
-----------	------

Electrical Specifications

Power Per Metre	4.8 W/m
Voltage	24 V dc

Approvals

Standards/Approvals	CE, RoHS
---------------------	----------

Mechanical Specifications

Strip Length	5 m
Strip Width	8 mm

