


REF : DUAL 22

Unbalanced audio cable - 0,22 mm²

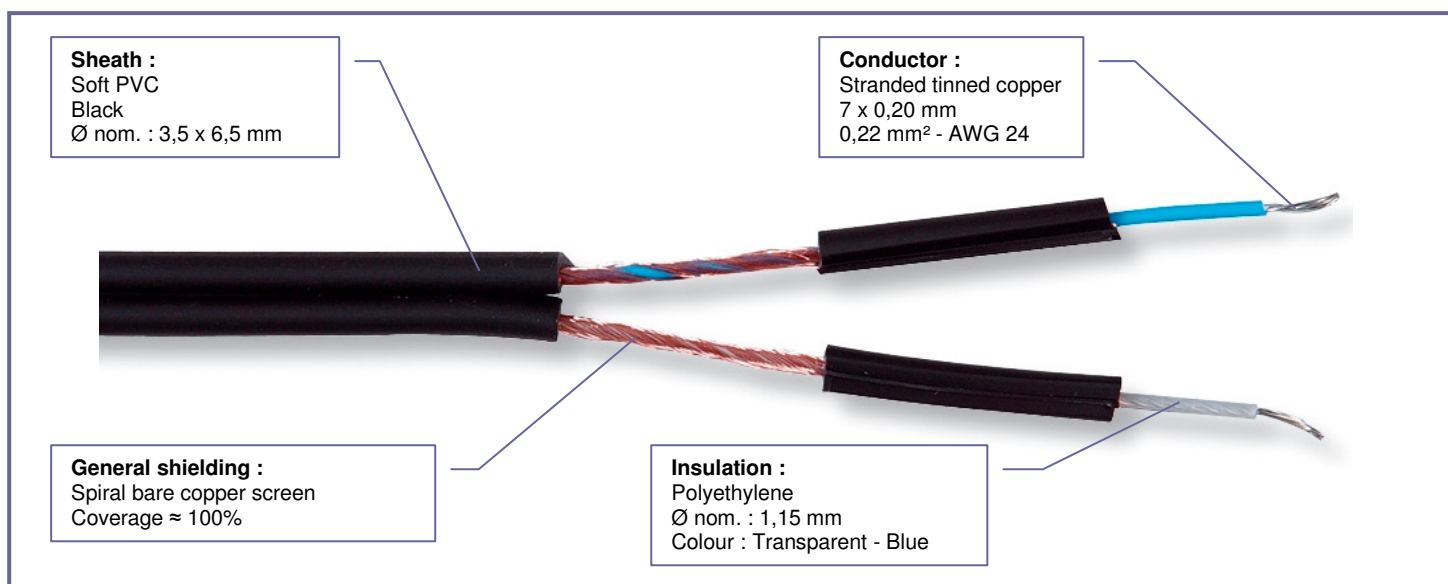

PRODUCT INFORMATIONS

Application

Cable for analogue unbalanced audio for mobile and fixed applications.
Patch panels audio
Hi fi.
For cords like cinch/cinch and jack/cinch.

Electrical properties

Max. voltage : 250 V

Test voltage : 1000 V

 
Intensity : 1,5 A

Capacitance : 170 pF/m

Inner conductor resistance at 20 °C : 85 Ω/km

Insulation resistance at 20 °C : > 500 MΩ.km

Characteristics



Temperature rating :
- 20 °C → + 70 °C



Minimum bending radius :
Fixed use : 25 mm
Mobile use : 50 mm



Weight :
40 kg/km



Conform to RoHS directive