



ENGLISH

Datasheet

**RS Pro Midget Flange Filament Indicator Lamp, Clear, 6 V, 40 mA, 10000h**

RS Stock No: **360-7547**

## Product Details

RS Pro midget flange filament indicator lamp works with currents up to 40 mA and voltages up to 6 V. This clear light delivers 0.5 lumens of bright output with a lifetime of 10000 hours.

## Features and Benefits

- Clear light
- 0.5 lumens output
- 10000 hours lifetime




ENGLISH

### Specifications:

Current Rating	40 mA
Diameter	5.84 mm
Lamp Base	Midget Flange
Lamp Size	T1 3/4
Length	15.87 mm
Lens Colour	Clear
Life Hours	10000 h
Luminosity	0.5 lm
Voltage Rating	6 V

*DRAWING - I*

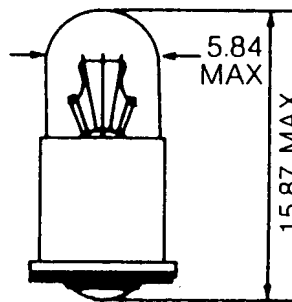

Unit : mm

1. Structure	Bulb Diameter	5.84mm Max.
	Length	15.87mm Max.
	Base Type	Midget Flange
2. Design Characteristics	Voltage	6V
	Amperage	40mA $\pm$ 10%
	Filament Type	C-2R
		Vacuum type
	MSCP	0.04 CP $\pm$ 20%
	Life Hours	10000 Hrs