

Datasheet

RS PRO VINYL-INSULATED (MOLDED EASY ENTRY) PIN TERMINALS

Stock number: 178-8429

MAXIMUM ELECTRIC CURRENT:

A.W.G.	16	14
AMP.	18	30


MAXIMUM ELECTRICAL RATING: 105° C 600 VOLTS MAX.

INSULATION MATERIAL: VINYL

TERMINAL MATERIAL: COPPER

INSULATION COLOR: BLUE

TERMINAL BARREL I.D.: C=2.3MM

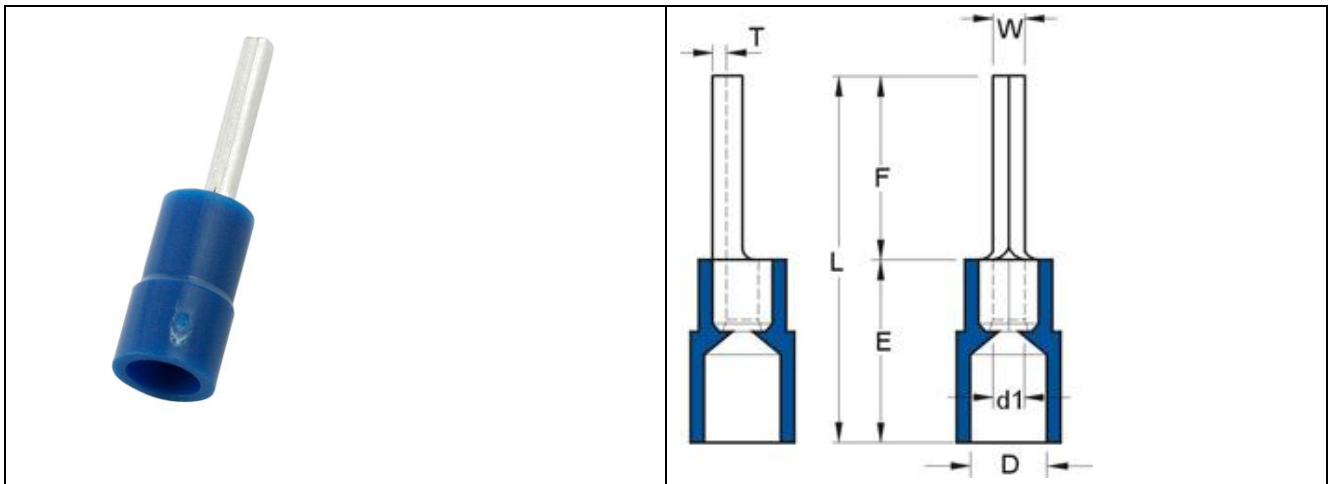

WIRE RANGE A.W.G. mm ²	ITEM NO. BUTTED SEAM	DIMENSION inch(mm)						
		W	F	L	E	D	d1	T
16-14 A.W.G.	178-8429	0.075	0.472	0.898	0.433	0.177	0.091	0.031
1.5-2.5 mm ²		1.9	12	22.8	11	4.500	2.3	0.8