




Orthomat® Premium Bubble

Our new Extraordinary anti-fatigue mat with a distinctive bubbled surface



- Exceptional fatigue-relief and fatigue-prevention properties.
- Dual layer construction for superior comfort and durability.
- Raised bubble patterned surface stimulates feet and legs aids circulation and prevents fatigue.
- Tough top surface for excellent resilience against wear and tear.
- Low density under layer provides extremely effective underfoot cushioning and insulates against the effects of cold concrete floors.
- Raised bubble pattern also reduces slips risk.
- Ideal for demanding locations, especially where regular turning is involved.
- Tapered edges to reduce trip hazards.
- Available in a high visibility version with bright yellow borders.

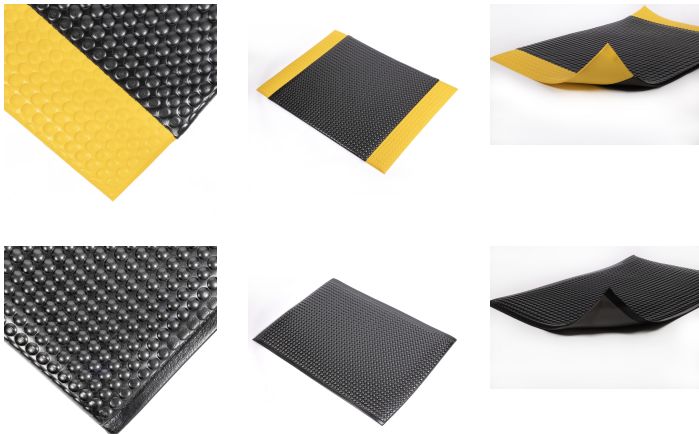

Styles Available



Black



Black/Yellow

Part Number	Size	Colour	Weight (kg)
OPB010003C	0.9 m x per linear metre	Black	3.58
OPB010703C	0.9 m x per linear metre	Black/Yellow	3.58
OPB010703	0.9 m x 18.3 m	Black/Yellow	65.55
OPB010702	0.9 m x 1.5 m	Black/Yellow	5.37
OPB010701	0.6 m x 0.9 m	Black/Yellow	2.15
OPB010003	0.9 m x 18.3 m	Black	65.55
OPB010002	0.9 m x 1.5 m	Black	5.37
OPB010001	0.6 m x 0.9 m	Black	2.15

Material	Open Cell PVC Foam
Surface Finish	Raised Bubble Pattern surface
Product Height	12.5mm base/16mm with Bubble
Product Weight	3.98Kg per square metre
Min. Operating Temperature	0°C
Max. Operating Temperature	+60°C
Resistance to Chemicals	Resistant to most chemicals
Environmental Resistance	Suitable for dry indoor environments
Typical Applications	production lines, assembly areas, packaging stations, workbenches and retail counters
Installation Method	Loose lay
Accessories	Bevelled edging
COO (Country of Origin)	CN
Guarantee	2 years when used in a dry environment

Get in touch | To order FREE samples or arrange a site visit please call +44 (0)1788 228 555 or email sales@coba.com

www.coba.com