

COVERALL

CV255M & CV255F

PRODUCT DESCRIPTION

The new ProGARM CV255 Coverall delivers 8cal/cm² ELIM protection with unparalleled comfort performance with a range of cutting-edge enhancements.

Featuring Generation 2 Fit improvements, it offers superior comfort and freedom of movement, ensuring optimal performance in demanding environments. The addition of FR HEX heat-applied tape enhances durability and safety, while its 100x wash resistance and industrial wash capability ensure long-lasting reliability.

Crafted with yarn-dyed fabric for exceptional colour retention, this upgraded coverall maintains a professional look even after rigorous use, making it the ultimate choice for linesmen who demand the best in arc protection and durability.

PRODUCT DETAILS

FITS: Male & Female

MALE SIZES: S-4XL Short | Regular | Tall (CV255M)

FEMALE SIZES: 6-18 Regular (CV255F)

 
COLOUR: HV Yellow & Navy with Reflective Tape



BOX TEST ARC RATING FABRIC



EN STANDARDS



COVERALL

CV255M & CV255F

FEATURES & BENEFITS

- ✓ 2 front chest pockets with zip and spot Velcro® closure
- ✓ 2 radio loops on the chest
- ✓ Ergonomic shaped elbow
- ✓ Left sleeve pocket built into paneling
- ✓ Hip pockets with flap to protect from debris
- ✓ Spacious bellow pocket with concealed Velcro® flap closure and contrast grab tabs
- ✓ Concealed 'D' ring to inner pocket
- ✓ Top loading knee pad pocket
- ✓ Pre-bent knees for easy bending
- ✓ Bellowed back pocket with contrast grab tabs
- ✓ Fixed elasticated waistband ensures a close fit
- ✓ Triple stitched side seams covered by lifetime guarantee
- ✓ Action back to allow for extra movement
- ✓ Thigh pockets include mobile pocket and knife pocket
- ✓ Increased length leg zip opening, allowing for improved donning and doffing
- ✓ Navy hem to show less dirt
- ✓ Velcro® back leg adjustment
- ✓ Hi-vis yellow lower leg with 50mm HEX FR reflective heat seal tape circling the lower leg

FABRIC SPECIFICATION:

- ✓ Weight: 250gms
- ✓ VXS+ Woven Yarn Dyed Fabric with FC Finish

PRODUCT CARE:



G2 Fit improvements and features enhancements



FR HEX Heat applied tape, 100x wash resistant, industrial wash capable



Yarn dyed fabric for better colour performance



LIFETIME SEAM
GUARANTEE

COVERALL

WEARER FIT GUIDE - FEMALE

STOCKED GARMENTS

Regular Fit Sizes 8-18 are stocked.

Lead times will apply for some fit and size combinations. Contact us to find out specific details.

BODY MEASUREMENTS

SIZE	BUST (cm / Inches)		WAIST (cm / Inches)		HIP (cm / Inches)	
6	81-96cm	32-34"	65-70cm	26-28"	88-93cm	35-37"
8	86-91cm	34-36"	70-75cm	28-30"	93-98cm	37-39"
10	91-96cm	36-38"	75-80cm	30-31"	98-103cm	39-41"
12	96-101cm	38-40"	80-85cm	31-33"	103-108cm	41-43"
14	101-106cm	40-42"	85-90cm	33-35"	108-113cm	43-44"
16	106-111cm	42-44"	90-95cm	35-37"	113-118cm	44-46"
18	111-116cm	44-46"	95-100cm	37-39"	118-123cm	46-48"
20	116-121cm	46-48"	100-105cm	39-41"	123-128cm	48-50"
22	121-126cm	48-50"	105-110cm	41-43"	128-133cm	50-52"
24	126-131cm	50-52"	110-115cm	43-45"	133-138cm	52-54"
26	131-136cm	52-54"	115-120cm	45-47"	138-143cm	54-56"

GARMENT LENGTH

SIZE	WEARER HEIGHT (cm / Inches)	WEARER INSIDE LEG (cm / Inches)
Short	160-170cm 5'4" - 5'7"	73cm 29"
Regular	170-180cm 5'7" - 5'11"	78cm 31"
Tall	180-188cm 5'11"-6'2"	84cm 33"

MEASURING GUIDE

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear. The tape measure should be fairly loose and not pulled too tight.

- ✓ **BUST** - measure under the arms at the fullest part around the bust horizontally with arms by your side
- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **HIP** - with the feet together measure around the fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor


Once measurements are taken compare them to the fit guide measurement tables to find your Jacket and Trouser size.

When fitting the Trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

**These styles are historically perceived as FEMALE but can be worn by any person whose body measurements fit into the above tables.*

***Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.*

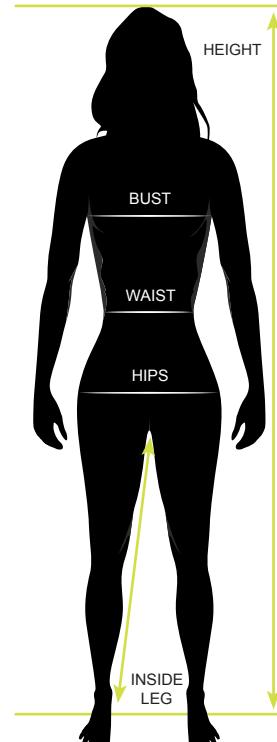

COVERALL

WEARER FIT GUIDE - MALE

STOCKED GARMENTS

Regular Fit Sizes S-4XL, and Tall Fit Sizes M-2XL are stocked.

Lead times will apply for some fit and size combinations. Contact us to find out specific details.

BODY MEASUREMENTS

SIZE	CHEST (cm / Inches)		WAIST (cm / Inches)		SEAT (cm / Inches)	
Small	94-96cm	37-38"	83-85cm	32-33"	90-92cm	35-36"
Medium	96-106cm	38-42"	85-95cm	33-37"	92-102cm	36-40"
Large	106-116cm	42-45"	95-105cm	37-41"	102-112cm	40-44"
X-Large	116-126cm	45-49"	105-115cm	41-45"	112-122cm	44-48"
2X-Large	126-136cm	49-53"	115-125cm	45-49"	122-132cm	48-52"
3X-Large	136-146cm	53-57"	125-135cm	49-53"	132-142cm	52-56"
4X-Large	146-156cm	57-61"	135-145cm	53-57"	142-152cm	56-60"
5X-Large	156-166cm	61-65"	145-155cm	57-61"	152-162cm	60-64"
6X-Large	166-176cm	65-69"	155-165cm	61-65"	162-172cm	64-68"

GARMENT LENGTH

SIZE	WEARER HEIGHT (cm / Inches)	WEARER INSIDE LEG (cm / Inches)
Short	160 -170cm 5'4" - 5'7"	73cm 29"
Regular	170 -180cm 5'7" - 5'11"	78cm 31"
Tall	180-188cm 5'11"-6'2"	83cm 33"

MEASURING GUIDE

Measurements must be taken wearing clothing usually worn underneath waterproof outerwear. The tape measure should be fairly loose and not pulled too tight.

- ✓ **CHEST** - measure under the arms at the fullest part around the chest horizontally with arms by your side
- ✓ **WAIST** - measure around the natural waistline at the fullest part
- ✓ **SEAT** - with the feet together measure around the fullest part of the hips
- ✓ **HEIGHT** - with bare feet together measure from the top of the head to the floor
- ✓ **INSIDE LEG** - in bare feet take the measurement from the top of the inside leg and measure down the inside leg to the floor

Once measurements are taken compare them to the fit guide measurement tables to find your Jacket and Trouser size.

When fitting the Trouser if the waist and seat measurements fall into different size categories then choose the larger size to ensure the trouser is not too close fitting.

If the height and inside leg measurements fall into different length categories then choose the jacket length based on the height measurement and the trouser length based on the inside leg measurement.

**These styles are historically perceived as MALE but can be worn by any person who's body measurements fit into the above tables.*

***Please note when using the measurement tables that all manufacturing tolerances and standard garment over-measures have been taken into account. This ensures any slight variances in manufacture or fabric shrinkage after washing will not affect the fit of the garments.*

