




HYDNUT150-HEAVY [🔗](#)

Hydraulic nut

HYDNUT..-HEAVY

Technical information

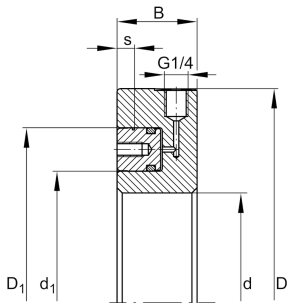

Your current product variant

Series	HEAVY	reinforced version without thread
--------	-------	-----------------------------------

Technical data

d	150 mm	Inner diameter (tolerance: H7)
D	270 mm	Outer Diameter
B	46 mm	Width
D 1	226 mm	
d 1	180 mm	
s	10 mm	Stroke, max.
	147 cm²	Piston surface
	600 bar	Pressure, max.
	880 kN	Drive-up force, max.
≈m	14.1 kg	Weight

Additional information

1 pc. Hydraulic nut, 1 pc. Screw plug, 1 pc. Connection nipple, 1 pc. Replacement seal set, 1 pc. User manual	Delivery scope
---	----------------