


2000.ROLL6M3G | MAINTENANCE WORKBENCH – 6 DRAWERS, GALVANIZED TOP, 2 M




Description :

- 6 drawers unit: - 3 drawers 60 mm. - 2 drawers 130 mm. - 1 drawer 200 mm. • The drawers can be fitted with thermoshaped and foam modules Maximum load resistance per drawer : 20/25/30 kg. • Polypropylène drawer pulls with safety hooks. - Lock on side to reduce the risk of damage. Centralized locking system, delivered with 2 keys, one folding. • Leg: - Steel sheet « U » profile. - Arranged for ground fixing. • Worktop: - 2.5 mm shock- and heat-resistant galvanised metal sheet. - 30 mm Safety edges on 3 sides with rounded and smooth border to avoid injuries. - Spread load resistance: 800 kg. • Accessories: - Integrated holder for cans or bottles (Free positioning on right or left). - Sides of the drawer unit are perforated to receive most of the JETXL accessories range (F13 catalogue). - Metal partitions can be provided in option (JET2.15 for 60 mm drawers and JET2.16 for 130 mm drawers). • Easy and fast assembly. • Drawer useful size: L.569 x D.421 x H.60 / 130 / 200 mm.

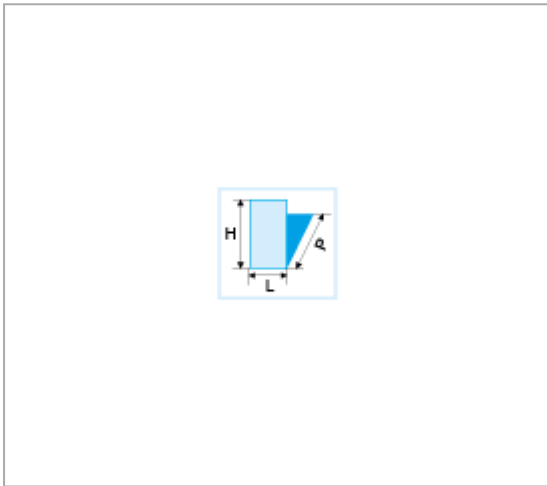

Informations :

	2000.ROLL6M3G
H [mm]	850
L [mm]	2000
P [mm]	700
Color	Red 3020
[kg]	87.,00