

Type MS116 Accessories


5



HK1-11



HKF1-11

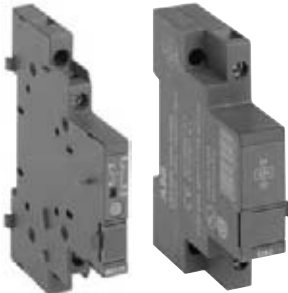

SK1-11

UA1-120



OTPA116



12644

Auxiliary contact blocks for Type MS116 (side mount)

Contact configuration	Catalog number	List price
1 NO & 1 NC 2 NO 2 NC	HK1-11 HK1-20 HK1-02	\$ 33

Auxiliary contact blocks for Type MS116 (front mount)

Contact configuration	Catalog number	List price
1 NO & 1 NC	HKF1-11	\$ 33

Bell alarm contact blocks for Type MS116

Contact configuration	Catalog number	List price
1 NO & 1 NC 2 NO 2 NC	SK1-11 SK1-20 SK1-02	\$ 33

Undervoltage trip for Type MS116

Voltage (VAC)	Catalog number	List price
24 48 60 120 230 400 415	UA1-24 UA1-48 UA1-60 UA1-120 UA1-230 UA1-400 UA1-415	\$ 82.50

Undervoltage trip with 1NO & 1NC auxiliary contact for Type MS116

Voltage (VAC)	Catalog number	List price
24 48 60 120 230 400 415	UA1-HK-24 UA1-HK-48 UA1-HK-60 UA1-HK-120 UA1-HK-230 UA1-HK-400 UA1-HK-415	\$ 97.50

Locking device for Type MS116

Description	Catalog number	List price
Adaptor for padlock Type SA1	MS325-SA1	\$ 15.00
Complete padlock locking kit (adaptor, padlock & 3 keys)	MS325-SA3	37.50

Molded plastic enclosures for Type MS116

Item description	Protection level	Catalog number	List price
Gray enclosure with black handle	IP64	OTPA116L2P1	\$ 75
Yellow enclosure with red handle	IP64	OTPA116A2P1	75
Gray enclosure with clear cover, 4 module	IP55	12644	84
Gray enclosure with clear cover, 6 module	IP55	12646	98
Gray enclosure with black handle	IP65	IB116-G	75
Yellow enclosure with red handle	IP65	IB116-Y	75

Plastic adaptors for enclosures for Type MS116


Description	Catalog number	List price
PG16 to 1/2NPT	PG16-1/2NPT	\$ 10

Shunt trip for Type MS116

Voltage (VAC)	Catalog number	List price
24V 110V 200 – 240V 350 – 415V	AA1-24 AA1-110 AA1-230 AA1-400	\$ 75

Type MS116 Accessories

5

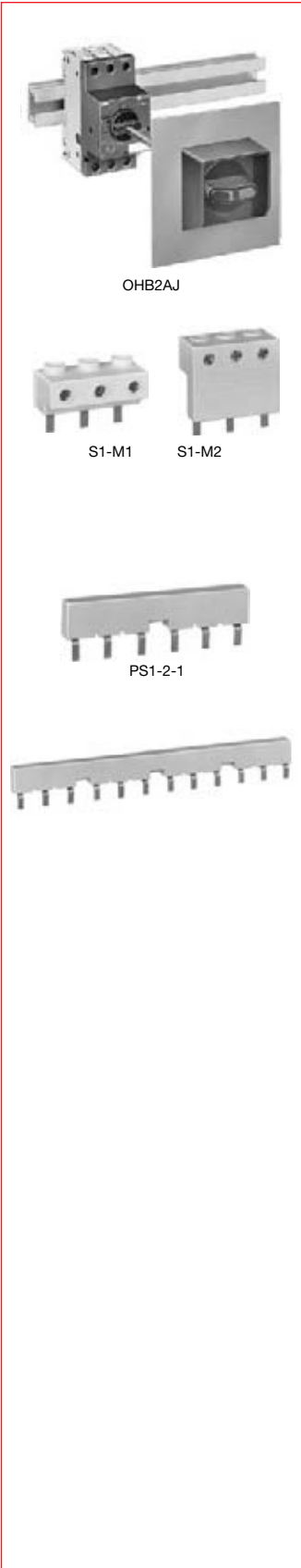

Door mounting hardware for for Type MS116 ①

Description	Catalog number	List price
Shaft coupler	MSMN	\$ 15
NEMA 1, 3R, 12 Black selector handle	OHB2AJ	30
NEMA 1, 3R, 12 Red, yellow selector handle	OHY2AJ	30
4.1" length shaft	OXS5X105	4
7.1" length shaft	OXS5X180	6

Power feed terminal blocks for Type MS116


Description	Catalog number	List price
for 4 AWG wire	S1-M1	\$ 24
for busbar	S1-M2	

Busbars for Type MS116

Description	Catalog number	List price
for 2 devices without auxiliary contacts	PS1-2-0	\$ 24
for 3 devices without auxiliary contacts	PS1-3-0	30
for 4 devices without auxiliary contacts	PS1-4-0	36
for 5 devices without auxiliary contacts	PS1-5-0	42
for 2 devices with 1 auxiliary contact	PS1-2-1	24
for 3 devices with 1 auxiliary contact	PS1-3-1	30
for 4 devices with 1 auxiliary contact	PS1-4-1	36
for 5 devices with 1 auxiliary contact	PS1-5-1	42
for 2 devices with 2 auxiliary contacts	PS1-2-2	24
for 3 devices with 2 auxiliary contacts	PS1-3-2	30
for 4 devices with 2 auxiliary contacts	PS1-4-2	36
for 5 devices with 2 auxiliary contacts	PS1-5-2	42

Busbar for direct mounting of contactors

Description	Catalog number	List price
B6/B7	BEA7/116	\$ 12.00
A9/A12/A16	BEA16/116	13.50
A26	BEA26/116	15.00
AL9 - AL16	BEA16/116AL	14.50

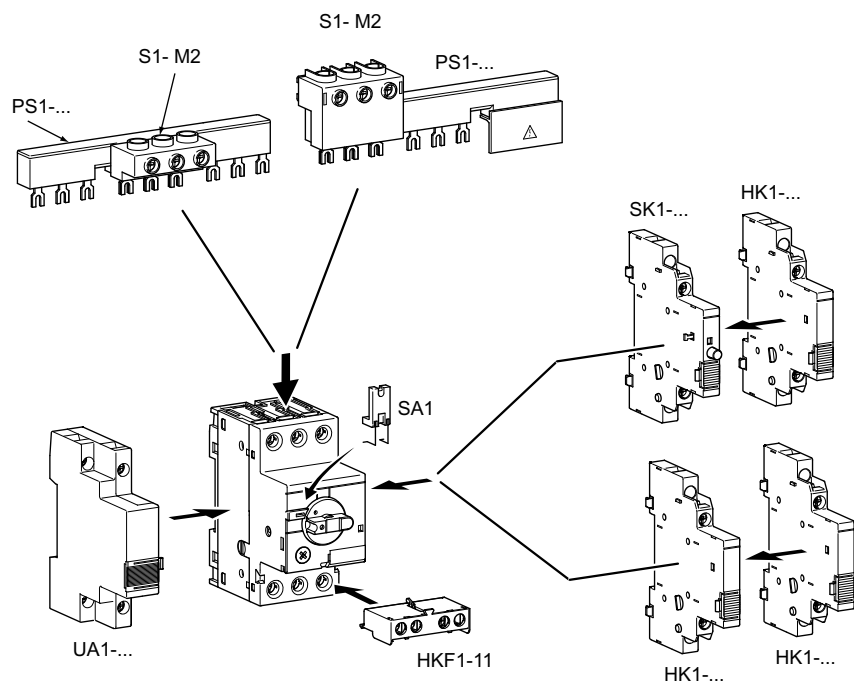

① Must have shaft coupler, handle and shaft for through-the-door operation.