


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0015060141](#)  
**Status:** **Active**  
**Overview:** Mini-Fit BMI Connectors  
**Description:** Mini-Fit BMI Receptacle Housing, 4.20mm Pitch, Dual Row with Panel Mount Ears, PA Polyamide Nylon 6/6, UL 94V-0, 14 Circuits

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-42474-001-001 (PDF)</a>
<a href="#">3D Model</a>	<a href="#">Test Summary TS-5556-002-001 (PDF)</a>
<a href="#">Product Specification PS-45750-001-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>
<a href="#">Product Specification PS-5556-002-001 (PDF)</a>	

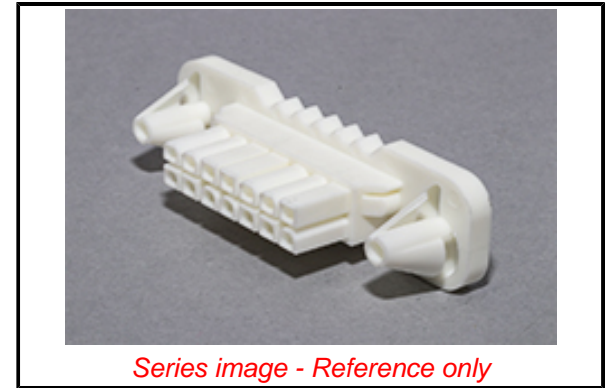

Series image - Reference only

**Agency Certification**

CSA	LR19980
UL	E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">42474</a>
3D Viewer	Yes
Application	Power, Wire-to-Board, Wire-to-Wire
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with <a href="#">45750</a> series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information.
Comments	Current = 13A max. per circuit when header is mated to a receptacle loaded with <a href="#">45750</a> series terminals crimped to 16 AWG wire. . See Molex product specification PS-45750-001 for additional current derating information.
Overview	<a href="#">Mini-Fit BMI Connectors</a>
Product Name	Mini-Fit BMI
UPC	800753741850

**Physical**

Breakaway	No
Circuits (maximum)	14
Color - Resin	Natural (White)
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	No
Lock to Mating Part	None
Material - Resin	Nylon
Net Weight	5.560/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	Yes
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

**Electrical**

Current - Maximum per Contact	13.0A
-------------------------------	-------

**Solder Process Data**

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[42474](#) Series

**Mates With**

[42475](#) MiniFit BMI Plug Housing. [43879](#) MiniFit CPI Header. MiniFit BMI Header [42404](#) , [42440](#). MiniFit SMC Surface Mount Compatible Header [43810](#) , [44068](#)

**Use With**

[5556](#) Mini-Fit Female Crimp Terminals, [45750](#) Mini-Fit Plus HCS Crimp Terminal

Lead-freeProcess Capability

N/A

**Material Info**

Engineering Number

42474-1421

**Reference - Drawing Numbers**

Packaging Specification

PK-42474-001-001

Product Specification

PS-45750-001-001, PS-5556-002-001

Sales Drawing

SD-42474-XXXX

Test Summary

TS-5556-002-001

This document was generated on 08/15/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**