



Figure similar

| Model | | |
|---|----|---------|
| product brand name | | SENTRON |
| Type of the driving mechanism | | others |
| General technical data | | |
| Electrical input frequency / minimum | Hz | 50 |
| Electrical input frequency / maximum | Hz | 50 |
| Manner of function / of the operating hours counter | | analog |
| Reset function | | no |
| Protection class | | |
| Protection class IP | | IP20 |
| Number | | |
| Number of characters that can be displayed | | 7 |
| Mechanical Design | | |
| Height | mm | 90 |
| Height / of the front plate | mm | 45 |
| Width | mm | 36 |

| | | |
|-----------------------|----|----------|
| Installation depth | mm | 64 |
| Number of width units | | 2 |
| Mounting type | | DIN rail |
| Net weight | g | 90 |

General Product Approval

Declaration of Conformity



Further information

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://eb.automation.siemens.com/mall/en/WW/Catalog/Product/7KT5802>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/7KT5802/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=7KT5802

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://ausschreibungstexte.siemens.com/tiplv>

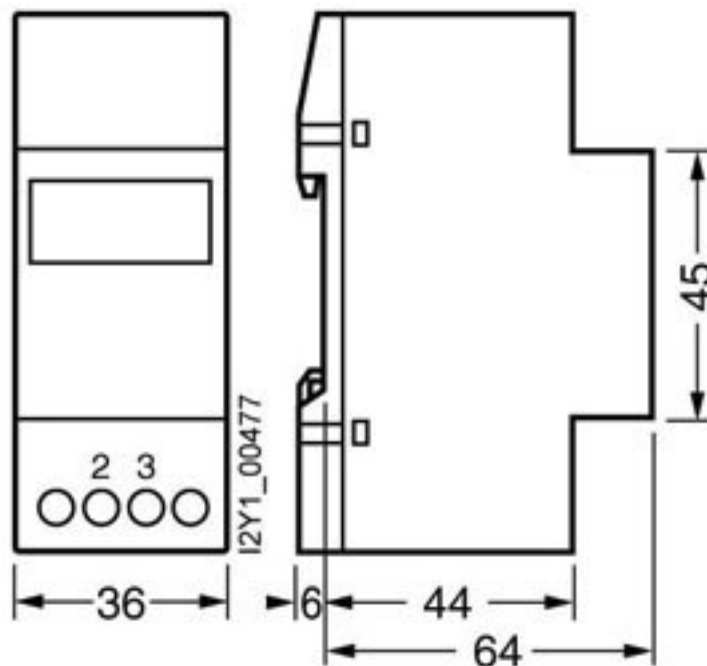

last modified:

08/30/2016