

# Universal socket strip 5-fold (type E) with switch

Item-No.: 0201x02052301 (1,5 m cord) | 0201x02052303 (3 m cord) | 0201x02052305 (5 m cord)



Robust plastic, grey

Built-in sockets (90° rotated), round

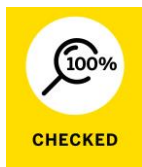
Extra large space in between sockets 64 mm

1,5 m power cord and angle plug (optional with 3 m or 5 m power cord)

Expanded contact protection by using a shutter




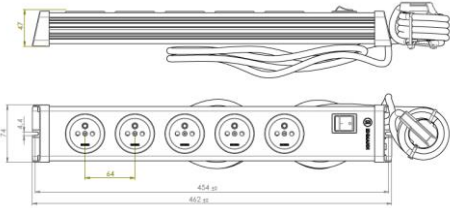
End caps with mounting possibility

With resettable circuit breaker 16A



## Universal socket strip 5-fold (type E) with switch

### Technical data

3.600 W Power	230 V ~ (+/- 10%) / 50 Hz Rated voltage	16 A Rated current									
Power Cord: H05VV-F 3G 1,5 mm <sup>2</sup> Plug: CEE 7/7 plug Type EF, angled Sockets: type E (French standard) Switch: 2-pole, illuminated (red) Consumption per switch: < 0,5 W Safety class: IP20 Protection: resettable circuit breaker 16A		  									
 <p>(similar illustration)</p>											
<table border="0"> <tr> <td>Item-No. 0201x02052301 (1,5 m cord)</td> <td>EAN 4012096021001</td> <td>PU 10</td> </tr> <tr> <td>Item-No. 0201x02052303 (3 m cord)</td> <td>EAN 4012096007821</td> <td>PU 10</td> </tr> <tr> <td>Item-No. 0201x02052305 (5 m cord)</td> <td>EAN 4012096013662</td> <td>PU 10</td> </tr> </table>		Item-No. 0201x02052301 (1,5 m cord)	EAN 4012096021001	PU 10	Item-No. 0201x02052303 (3 m cord)	EAN 4012096007821	PU 10	Item-No. 0201x02052305 (5 m cord)	EAN 4012096013662	PU 10	462 x 74 x 47 mm Dimensions (L x W x H) 454 mm Fixing Dimension
Item-No. 0201x02052301 (1,5 m cord)	EAN 4012096021001	PU 10									
Item-No. 0201x02052303 (3 m cord)	EAN 4012096007821	PU 10									
Item-No. 0201x02052305 (5 m cord)	EAN 4012096013662	PU 10									