


RS Part Number: **9143948**

Europa Part Number: **MT-TUA-17S-11-9240-7**

Specifications and dimensions

- Multifunction timer SPCO
- Din rail mounting
- LED indicator for power and run

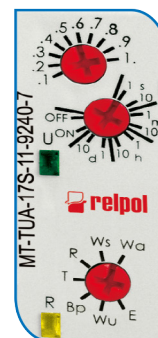

| Features | |
|---------------------------------|-----------------------|
| Height | 98.8mm |
| Width | 17.5mm |
| Depth | 63.5mm |
| Weight | 0.11Kg |
| Cover ingress protection | IP20 |
| Contact arrangement | 1 x C/O |
| Contact material | AgNi |
| Rated switching voltage | 250V AC |
| Minimum switching voltage | 5V |
| Rated load AC1 | 10A / 250VAC |
| Rated load DC1 | 10A / 24VDC |
| Rated voltage coil | 12 ... 240V AC/DC |
| Rated frequency | 48 ... 63 Hz |
| Rated power consumption of coil | 0.75VA |
| Coil resistance at 20°C | 38500 W |
| Electrical life AC1 | > 2x 10 ⁵ |
| Mechanical life | > 2 x 10 ⁷ |
| Operating temperature | , -20°C to +45°C |
| Timing Module Functions | |
| Delay on energisation | E |
| Delay on de-energisation | Wu |
| Symmetrical recycling | Bp |
| 0.5s pulse | T |
| Delay off with start contact | R |
| Interval with 0.5s pulse | Ws |
| Interval ON | Wa |
| Time Ranges | |
| Seconds | 1s, 10s |
| Minutes | 1m, 10m |
| Hours | 1h, 10h |
| Days | 1d, 10d |
| Setting accuracy | ± 5% |
| Repeat accuracy | ± 0.5% |

❗ ALL PRODUCTS, PRODUCT SPECIFICATIONS AND DATA ARE SUBJECT TO CHANGE WITHOUT NOTICE.

Information provided in data sheets and/or specifications may vary from actual results in different applications and performance may vary over time. **All products must be installed according to manufacturers instructions.**

Europa House, Airport Way, Luton, Beds, LU2 9NH Tel: 01582 692 440 / Fax: 01582 692 450 e-mail: sales@europacomponents.com
website: <http://www.europacomponents.com>