


Exhaust plate VABF-XA-12-M1-C

Part number: 8191741

FESTO

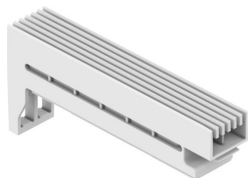

 [General operating condition](#)

Data sheet

Feature	Value
Size of pack	1
Compatible with	Valve terminal VTUX-A-P Valve terminal VTUX-A-S
Burst pressure	17 bar
Operating pressure	-0.1 MPa ... 0.7 MPa
Operating pressure	-1 bar ... 7 bar
Suitability for vacuum	no
Standard flow rate (standardised to DIN 1343)	5200 l/min
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C ... 70 °C
Sound pressure level	95 dB(A)
Sound power level at a distance of 1 m	106 dB(A)
Product weight	24.9 g
Type of mounting	Snapping in
Note on materials	RoHS-compliant
Material housing	PA-reinforced
Material silencer	PE