


Vernier Calipers

Pocket Vernier Caliper

DIN 862

- professional standard caliper

- inox, hardened
- graduation in mm/inch, scale etched
- reading satin chrome finish, flat depth gauge
- jaws finely ground and lapped

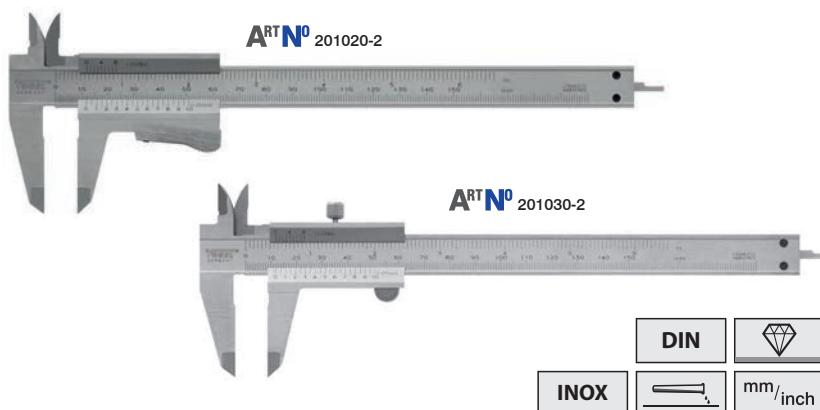


ART No thumb locking	ART No fixing screw	mm / inch	mm bottom	inch top	mm	mm	flat
201020-2	201030-2	150 / 6	0.05	1/128	40	16	flat

Pocket Vernier Caliper

DIN 862

- with parallaxfree reading

- stainless steel, hardened
- graduation in mm/inch, laser engraved scale
- reading satin chrome finish
- jaws finely ground and lapped, flat depth gauge
- mono-block vernier

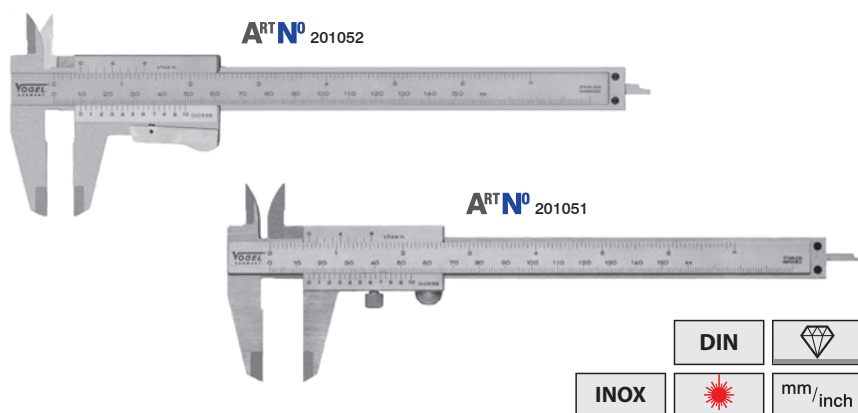


ART No thumb locking	ART No fixing screw	mm / inch	mm bottom	inch top	mm	mm	flat	CC
201052	201051	150 / 6	0.05	1/128	40	16	flat	on request

Pocket Vernier Caliper

DIN 862

- for DIY requirements

- reading in mm/cm
- reading satin chrome finish
- hardened
- jaws fine ground
- with fixing screw
- flat depth gauge

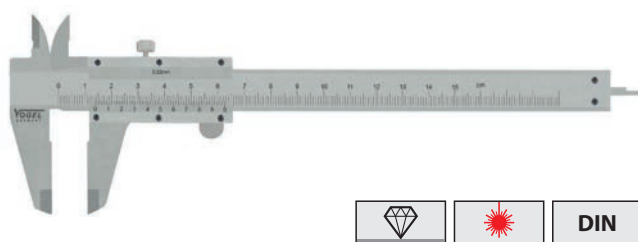

ART No	mm	mm	mm	mm	flat
201005	150	0.02	40	16	flat