


Self-aligning ball bearings, cylindrical and tapered bore

Principal dimensions			Basic load ratings		Fatigue	Speed ratings		Mass	Designation
d	D	B	dynamic C	static C_0	load limit P_u	Reference speed	Limiting speed		
mm			kN		kN	r/min		kg	-
40	80	23	19,9	6,95	0,36	-	5600	0,50	2208 E-2RS1TN9

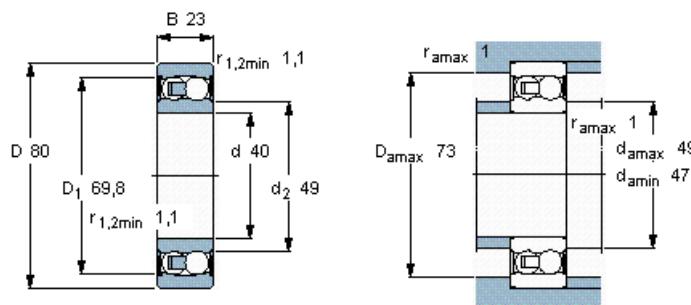

Calculation factors

e	0,22
γ_1	2,9
γ_2	4,5
γ_0	2,8