


LED system light

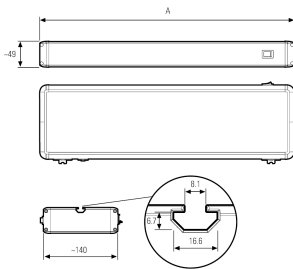

Product-Nr.	155420-02
EAN:	4260556627656
Model:	SYSTEMLED EVO - ECO Neutral White
Order number:	155420-02
Model:	SYSTEMLED EVO - ECO Neutral White
Type:	LED system light
Illuminant:	2 x LE-860e4000K
Total output incl. driver:	~51 W
Power consumption:	~46 W
Lamp luminous flux:	7960 lm
Lamp luminous efficiency:	173 lm/W
Light distribution:	direct
Light colour:	4000K 3-step MacAdam
R9:	90
Connected load:	120-277VAC, 50 - 60 Hz
Power supply:	integrated
Connection (connector):	Wieland GST18
Degree of protection:	IP40
Class of protection:	I
Glare control:	Microprisms
Beam angle (optics):	90°
Operating temperature:	-10 °C - +50 °C (14 °F - 122 °F)
Storage temperature:	-20 °C - +80 °C (-4 °F - 176 °F)
Colour rendering (Ra):	>90 (typ. 95)
Lamps lifetime:	> 100,000 h (L80/B10)
Housing material:	aluminum and PMMA
Height [B] x Width [C]:	48 mm x 139 mm (~1,89" x ~5,47")
Length [A]:	1782 mm (~70,16")
Mounting:	T-slot rear (8 mm)
Weight (net):	4700 g (~166 oz)
Gross weight:	6580 g (~232 oz)
Risk group (DIN EN 62471):	free group
Dimmable:	yes
Mounting accessories:	optional
Made in:	Germany