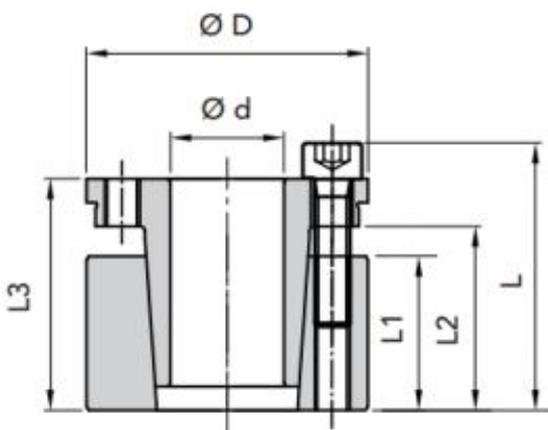


06700060

RCK 70 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06700060
Ød (DD) mm	60
ØD (D) mm	90
L1 (L1) mm	30
L2 (L2) mm	36
L3 (L3) mm	47
L (L) mm	55
Maximum torque Mt (MT) Nm	3380
Clamping pressure - Shaft (CPS) N/mm ²	198
Clamping pressure - Hub (CPH) N/mm ²	157
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	8
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M8x30
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	41
Extraction thread - Type (ETT)	M8
Extraction thread - Num. (ETN)	4
Weight (WEIGHT) kg	1.20