

3 ビス止めタイプ ビスで確実・強固な固定が可能 ナイロンクリップ

INSULOK®



標準グレード

屋内使用

色 乳白




材質 66ナイロン

UL難燃グレード(主原料) UL94V-2

常時使用温度範囲 -40℃~+85℃



結束バンドを使用せず、素早く簡単に配線を固定することができます。

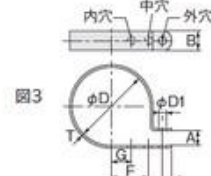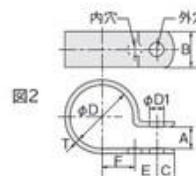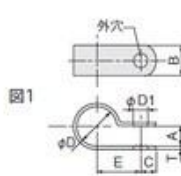

Article-No.	型番	図番	固定時の内径 φ (mm)			寸法(mm)										適用 ビス	販売単位(個)	
						φD	φD1	A	B	C	E	F	G	T	袋		ケース	
211-00191	AB-2N	1	3.0			3.3	4.3	3.2	9.5	4.8	9.5			1.1	M4	100	20,000	
211-00195	AB-3N	1	4.5			5.3	4.3	4.8	9.5	4.8	10.3			1.1	M4	100	20,000	
211-00198	AB-4N	1	6.0			6.8	4.3	4.8	9.5	4.8	11.1			1.1	M4	100	20,000	
211-00205	AB-5N	1	7.5			8.4	4.3	4.8	9.5	4.8	11.9			1.1	M4	100	10,000	
211-00207	AB-6N	1	9.5			10.6	4.3	6.3	9.5	4.8	12.7			1.1	M4	100	10,000	
211-00209	AB-7N	1	10.5			12.2	4.3	6.3	9.5	4.8	13.5			1.1	M4	100	10,000	
211-00211	AB-8N	1	11.5			13.2	4.3	6.3	9.5	4.8	14.3			1.1	M4	100	10,000	
211-00213	AB-9N	1	13.5			15.2	4.3	6.3	9.5	4.8	15.1			1.1	M4	100	10,000	
211-00175	AB-10N	1	14.5			16.0	4.3	6.3	9.5	4.8	15.9			1.1	M4	100	10,000	
211-00177	AB-11N	1	16.5			19.0	5.1	7.9	12.7	6.3	17.5			1.8	M5	100	4,000	
211-00179	AB-12N	1	17.5			19.8	5.1	7.9	12.7	6.3	18.2			1.8	M5	100	4,000	
211-00181	AB-13N	1	20.0			22.1	5.1	7.9	12.7	6.3	19.0			1.8	M5	100	4,000	
211-00183	AB-14N	2	21.0		19.0	22.9	5.1	7.9	12.7	6.3	19.8	11.9		1.8	M5	100	3,000	
211-00185	AB-16N	2	24.5		22.5	26.9	5.1	7.9	12.7	6.3	21.4	13.5		1.8	M5	100	3,000	
211-00187	AB-18N	2	27.0		24.5	29.2	5.1	7.9	12.7	6.3	23.0	15.1		1.8	M5	50	2,500	
211-00189	AB-24N	3	37.0	35.5	31.5	39.4	5.1	9.5	12.7	6.3	27.8	19.8	11.9	1.8	M5	50	1,000	
211-00193	AB-32N	3	49.0	47.0	43.5	52.1	5.1	9.5	12.7	6.3	34.1	24.6	13.5	1.8	M5	25	1,000	

耐候グレード

 
屋内外使用

色 黒

材質 66ナイロン

UL難燃グレード(主原料) UL94V-2

常時使用温度範囲 -40℃~+85℃



Article-No.	型番	図番	固定時の内径 φ (mm)			寸法(mm)										適用 ビス	販売単位(個)	
						φD	φD1	A	B	C	E	F	G	T	袋		ケース	
211-00192	AB-2N-W	1	3.0			3.3	4.3	3.2	9.5	4.8	9.5			1.1	M4	100	20,000	
211-00197	AB-3N-W	1	4.5			5.3	4.3	4.8	9.5	4.8	10.3			1.1	M4	100	20,000	
211-00204	AB-4N-W	1	6.0			6.8	4.3	4.8	9.5	4.8	11.1			1.1	M4	100	20,000	
211-00206	AB-5N-W	1	7.5			8.4	4.3	4.8	9.5	4.8	11.9			1.1	M4	100	10,000	
211-00208	AB-6N-W	1	9.5			10.6	4.3	6.3	9.5	4.8	12.7			1.1	M4	100	10,000	
211-00210	AB-7N-W	1	10.5			12.2	4.3	6.3	9.5	4.8	13.5			1.1	M4	100	10,000	
211-00212	AB-8N-W	1	11.5			13.2	4.3	6.3	9.5	4.8	14.3			1.1	M4	100	10,000	
211-00214	AB-9N-W	1	13.5			15.2	4.3	6.3	9.5	4.8	15.1			1.1	M4	100	10,000	
211-00176	AB-10N-W	1	14.5			16.0	4.3	6.3	9.5	4.8	15.9			1.1	M4	100	10,000	
211-00178	AB-11N-W	1	16.5			19.0	5.1	7.9	12.7	6.3	17.5			1.8	M5	100	4,000	
211-00180	AB-12N-W	1	17.5			19.8	5.1	7.9	12.7	6.3	18.2			1.8	M5	100	4,000	
211-00182	AB-13N-W	1	20.0			22.1	5.1	7.9	12.7	6.3	19.0			1.8	M5	100	4,000	
211-00184	AB-14N-W	2	21.0		19.0	22.9	5.1	7.9	12.7	6.3	19.8	11.9		1.8	M5	100	3,000	
211-00186	AB-16N-W	2	24.5		22.5	26.9	5.1	7.9	12.7	6.3	21.4	13.5		1.8	M5	100	3,000	
211-00188	AB-18N-W	2	27.0		24.5	29.2	5.1	7.9	12.7	6.3	23.0	15.1		1.8	M5	50	2,500	
211-00190	AB-24N-W	3	37.0	35.5	31.5	39.4	5.1	9.5	12.7	6.3	27.8	19.8	11.9	1.8	M5	50	1,000	
211-00194	AB-32N-W	3	49.0	47.0	43.5	52.1	5.1	9.5	12.7	6.3	34.1	24.6	13.5	1.8	M5	25	1,000	